




SIVACON, side panel / rear panel, Closed, IP40, H: 2000 mm, W: 800 mm, RAL 7035

Model	
product brand name	SIVACON
product designation	Side panel/rear panel
design of the product	Closed
design of the surface	Powder-coated
design of the product EMC version	No
Protection class	
protection class IP	IP40
Appearance	
RAL color number	RAL 7035
color	light grey
Product details	
product component	
• cable entry	No
• lock	No
Mechanical Design	
height	2 000 mm
width	800 mm
depth	800 mm
material	steel
Approvals Certificates	
General Product Approval	
Test Certificates	
other	
   Special Test Certificate Confirmation Miscellaneous	
other	Environment
Miscellaneous  Environmental Confirmations	

Further information	
Information on the packaging	
https://support.industry.siemens.com/cs/ww/en/view/109813875	
Information- and Downloadcenter (Catalogs, Brochures,...)	
http://www.siemens.com/lowvoltage/catalogs	

Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1080-2UW60-1C>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1080-2UW60-1C>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1080-2UW60-1C
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

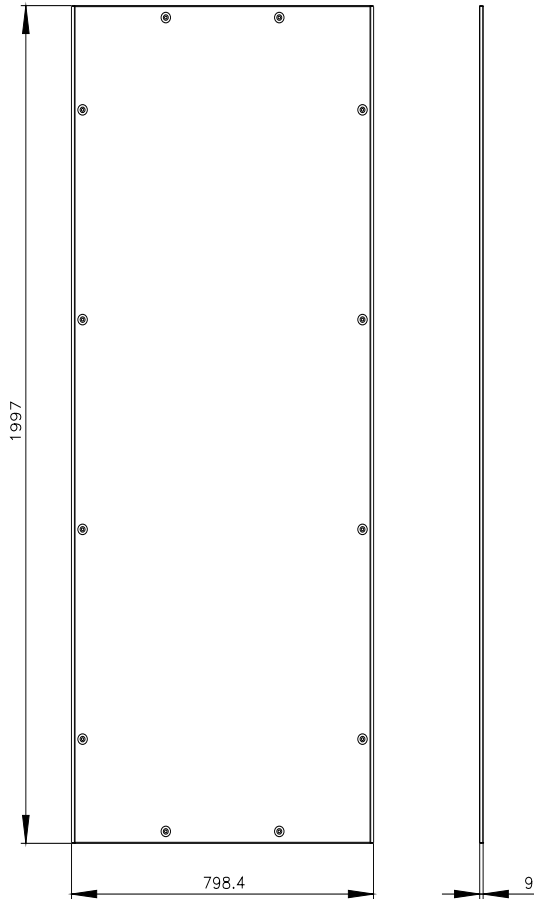

last modified: 2/12/2021

