




RUBBER ANTENNA RRST-MA11-5008-1M-FY-001

■ SPECIFICATION

PARAMETERS	VALUE
Center Frequency	868 MHz
Gain	2 dBi
Nominal Impedance	50 Ω
VSWR, max	2
Return Loss, max	-10 dB
Polarization	Linear
Radiation	Omni-directional
Connector	SMA Male
Operating Temperature Range	-40 ~ +85°C



■ MECHANICAL SPECIFICATIONS

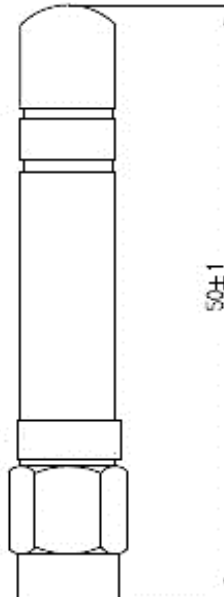

■ APPROVAL

RS PRO	
DRAWN BY:	AR, June 14, 2018
APPROVED BY:	CP, June 14, 2018
REVISION:	A, Initial Release