


Eaton 138363

Catalog Number: 138363

Eaton xEffect SASY 60i Enclosures Switch- & Controlgear Enclosure. Connection terminal 95-300 mm²

General specifications

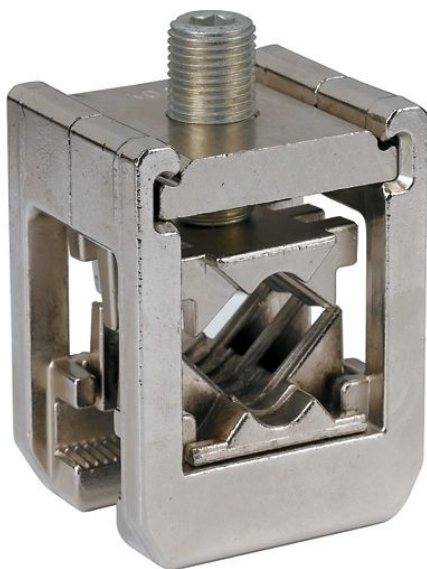

Product Name	Catalog Number
Eaton xEffect SASY 60i busbar terminal	138363
EAN	Product Length/Depth
4015081351435	100 mm
Product Height	Product Width
60 mm	48 mm
Product Weight	Compliances
0.857 kg	RoHS conform

Product specifications

Used with

Triple T profile
30 mm x 10 mm rail
Double T profile
Connection
60 mm system

Special features

Cable block is used to connect the conductor to the busbar

Type

60 mm system
Connection

Width clamp

48 mm

Busbar thickness - max

10 mm

Busbar thickness - min

10 mm

Busbar width - max

30 mm

Busbar width - min

30 mm

Conductor cross section - max

300 mm²

Rated operational current (I_e) - max

630 A

Functions

Connections
Terminal

Rated operation current (I_e)

630 A

Suitable for

Strip conductor connection
Round conductor connection
T-rail

Rated operational current

630 A

Resources

Brochures

[eaton-xeffect-sasy60i-customer-success-story-css-wagner-mueller-en-us.pdf](#)

Catalogs

Product Range Catalog Switching and protecting motors
[eaton-xeffect-sasy-60i-fk4300-1167gb-en-us.pdf](#)

Certification reports

[eaton-xeffect-sasy-60i-declaration-of-conformity.pdf](#)

Drawings

[eaton-control-panels-xeffect-sasy-terminal-3d-drawing-002.eps](#)

Terminal capacity (conductor)

95 mm² - 300 mm²



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are
property of their respective
owners.



Eaton.com/socialmedia