


## Datasheet

### SPDT Rocker Switch, ON-OFF-ON


RS Stock number 734-6924

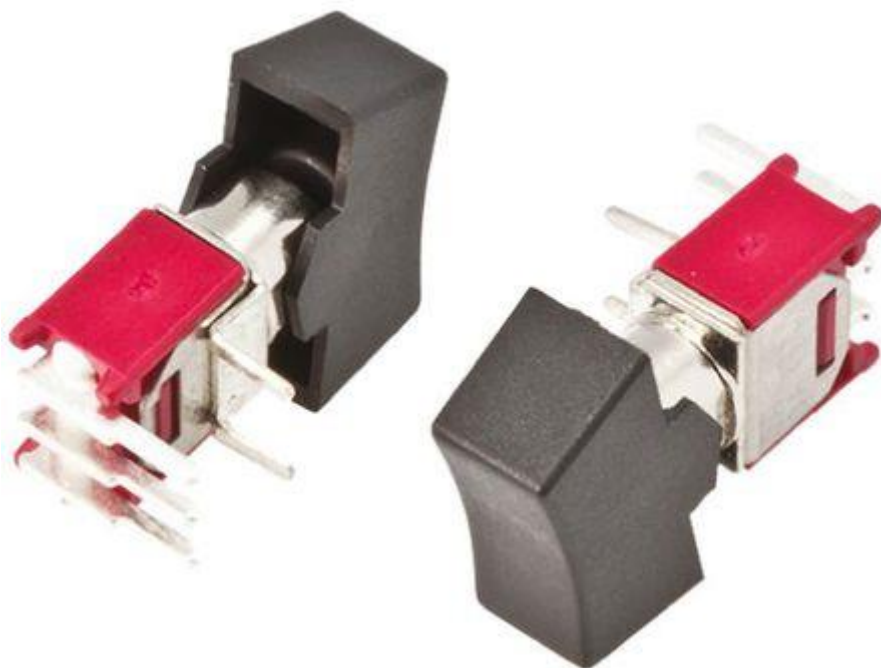

#### Specifications:

 
 
MECHANICAL LIFE:	30,000 make-and-break cycles.
CONTACT RESISTANCE:	20mΩmax. initial @ 2-4VDC 100mA for both silver and gold plated contacts.
INSULATION RESISTANCE:	1,000 MΩmin.
DIELECTRIC STRENGTH:	1,000Vrms min. @ sea level.
OPERATING TEMPERATURE:	-30°C to 85°C.
MATERIALS	
CASE:	Diallyl phthalate (DAP) (UL94V-0)
ACTUATOR:	Nylon, black standard.
SWITCH SUPPORT:	Brass, tin plated.
TERMINAL/CONTACT:	Brass, with silver or gold plated.
RoHS:	2002/95/EC

## Dimensions – inch mm

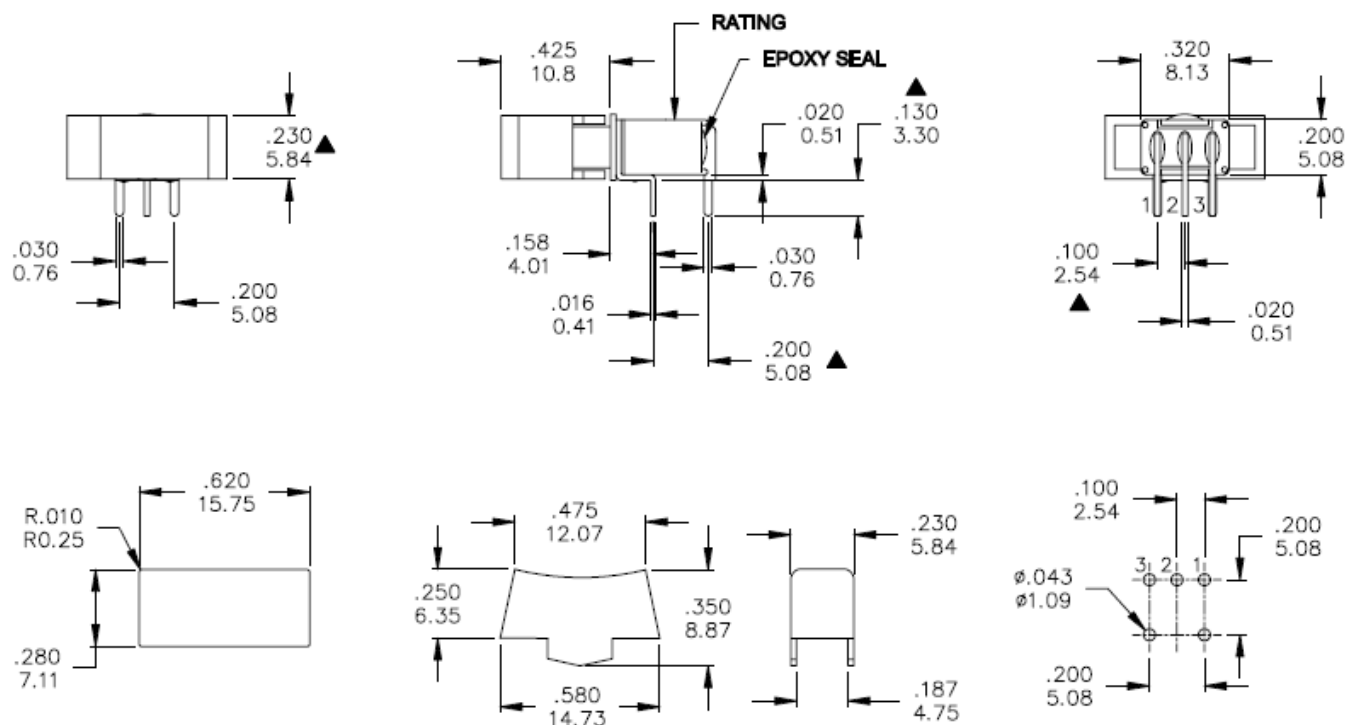

**PANEL MOUNTING**

**P.C. MOUNTING**

Model No.	POS.1	POS.2	POS.3
4MS3	ON	OFF	ON
Term. Comm.	2-3	OPEN	2-1
SCHEMATIC			

**SWITCH FUNCTION**