


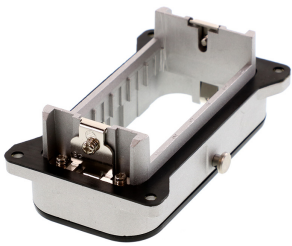

Part Number : [587190010](#)
Product Description : HMC Rectangular Industrial Panel-Mount Bracket, Multi-Module Type, 48-72 Circuits, Type A Polarization
Series Number : [58719](#)
Status : Obsolete
Product Category : [I/O Connectors](#)



Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Product not active
China RoHS	Product not active
EU ELV	Product not active
Low-Halogen Status	Product not active
REACH SVHC	Product not active
EU RoHS	Product not active

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Obsolete
--------	----------

Category	I/O Connectors
Series	58719
Description	HMC Rectangular Industrial Panel-Mount Bracket, Multi-Module Type, 48-72 Circuits, Type A Polarization
Application	Panel-Mount
Component Type	Panel-Mount Bracket
Product Name	HMC
Type	N/A
UPC	800753921078

Electrical

Current - Maximum per Contact	20.0A
Shield Type	Full Shield
Shielded	Yes
Voltage - Maximum	300V DC

Physical

Boot Color	N/A
Circuits (Loaded)	N/A
Circuits (maximum)	48
Durability (mating cycles max)	50
Gender	Receptacle
Lock to Mating Part	Yes
Material - Plating Mating	N/A
Net Weight	131282.800/mg
Number of Rows	2
Orientation	Vertical
Packaging Type	Bag
Panel Mount	Screws
PCB Locator	No
Pitch - Mating Interface	N/A
Polarized to Mating Part	Yes
Ports	1
Temperature Range - Operating	-55° to +125°C
Termination Interface Style	N/A

Waterproof / Dustproof	Yes
Waterproof / Dustproof Type	IP65