

## Features

- 22mm cutout
- IP65 rating
- Bright, 24V LED illumination in red
- Robust and stylish
- Fitted with pin terminals

## RS PRO 22mm Panel Indicator Light 24V Red LED, IP65

RS Stock No.: 0325301



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

These 22mm, round panel indicator lights are stylish and durable products. Rated IP65, they are highly suitable for applications within more challenging environments. They use excellent ABS material and a quality electroplating process which ensures they are not only robust but also reliable.

The button raises less than 2mm above the panel and the polycarbonate silver surround adds to the aesthetic quality of the switch. This, along with the bright LED illumination makes them a standout choice for any application.

## Electrical Specifications

### Specifications



Terminal type	Pin terminals (2.8x0.5mm)
Actuator shape	Round
Rated current	About 6mA
Life	About 40,000 hours
Insulation resistance	$\geq 100\text{M}\Omega$ (500VDC)
Dielectric strength	1500V, RMS 50Hz, 1min
Dropping way	Inner resistance
Operating temperature	-25°C~+55°C no freezing
Panel cut out	22mm
Lamp	LED 24V AC/DC
Colour	Red
IP degree	IP65

## MATERIALS:



1.HEAD: PC.

2.BODY: PC.


3.BASE: PBT.

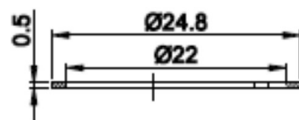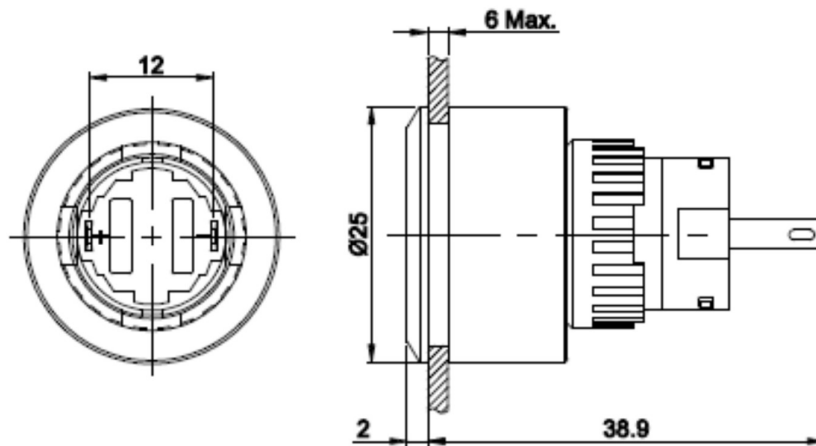

SEAL RING(IP40 HAS NO GASKET)

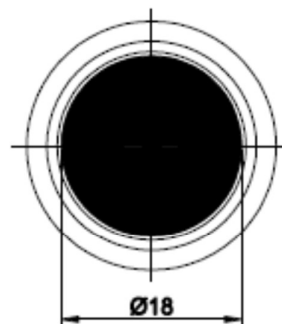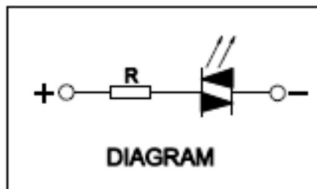

THE SHADED PART IS ILLUMINATED

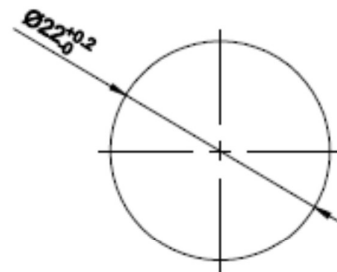

PANEL CUTOUT