



Figure similar

SITOR cylindrical fuse link, 14x51 mm, 5 A, aR, Un AC: 690 V, Un DC: 700 V, DC according to UL

Model			
product brand name		SENTRON	
product designation		SITOR cylindrical fuse link	
design of the product		DC acc. to UL	
General technical data			
operating class of the fuse link		aR	
type of voltage of the operating voltage		AC	
supply voltage at DC		700 V	
Dissipation			
power loss [W]		1.5 W	
power loss [W] for rated value of the current at AC in hot operating state per pole		2 W	
Main circuit			
operational current rated value		5 A	
Product details			
product component striker		No	
Mechanical Design			
mounting position		Any, preferably vertical	
net weight		21 g	
Approvals Certificates			
General Product Approval		other	Environment



[Confirmation](#)

[Environmental Confirmations](#)

Environment

[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NC1405>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3NC1405>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NC1405

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

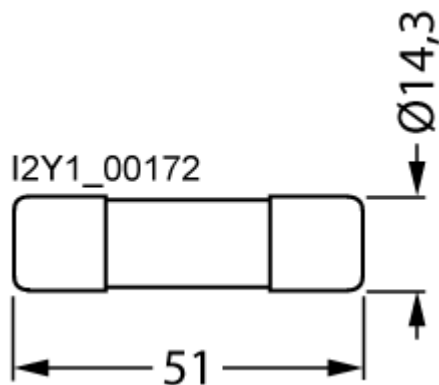

last modified:

4/11/2025 

