

Universe	Professional
Type	Lighting
Category	Ultra-compact headlamps
Subcategory	Ultra-compact headlamps



Hybrid
CONCEPT

TACTIKKA® +RGB


Designed for the workshop, small maintenance jobs, or concerts and shows, the TACTIKKA + RGB offers 350-lumen brightness and a mixed beam, for comfortable proximity lighting and rapid movement. It also has red, green or blue lighting to ensure stealth. TACTIKKA +RGB comes with 3 standard batteries and is also compatible with the CORE rechargeable battery, thanks to the HYBRID CONCEPT design. Mounting accessories allow the lamp to be attached to any kind of helmet.



Mixed beam for proximity and distance vision. White lighting, or red/green/blue for nighttime stealth.



Headband can be undone for easy donning.

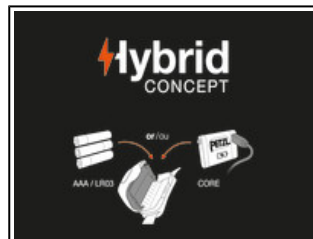

HYBRID CONCEPT design: TACTIKKA +RGB comes with three standard batteries and is also compatible with the CORE rechargeable battery.

Short Description

Compact headlamp with mixed beam for proximity and distance vision. White or red/green/blue lighting to ensure stealth. 350 lumens

Selling Points

- Lightweight, compact and bright:
 - 350 lumens at 85 g
 - three white brightness levels for comfortable proximity lighting and rapid movement
 - red, green or blue lighting (continuous or strobe) combines visual comfort and stealth
- Simple to use and practical:
 - single button for quick and easy selection of brightness or light color
 - ergonomic button, even with gloves
 - easy to put on via quick-release buckle on the headband
 - detachable, washable headband
 - HYBRID CONCEPT design: TACTIKKA +RGB comes with three standard batteries and is also compatible with the CORE rechargeable battery
 - compatible with mounting accessories that allow the lamp to be attached to any kind of helmet
- Available in three colors, depending on use

Specification

- Brightness: 350 lumens (ANSI/PLATO FL 1)
 - Weight: 85g
 - Beam pattern: mixed
 - Energy: Three AAA/LR03 batteries (included) or CORE rechargeable battery (available as accessory)
 - Battery compatibility: alkaline, lithium or Ni-MH rechargeable
 - Certification(s): CE
 - Watertightness: IPX4 (weather-resistant)
-

Lighting performance

Lighting color	Lighting levels	Brightness	Distance	Burn time	Reserve
white	proximity	6 lm	10 m	160 h	-
	movement	100 lm	45 m	12 h	30 h
	distance vision	350 lm	90 m	2 h	60 h
red/green/blue	proximity	2 lm	5 m	60 h	-
	strobe	visible at 700 m for 400 h			

Specifications by reference

Reference(s)	E089FA00	E089FA01	E089FA02
			
Color(s)	black	camo	desert
Made in	FR	FR	FR
Guarantee	5 years	5 years	5 years
Packing	1	1	1
Case quantity	50	50	50
EAN	3342540827899	3342540827905	3342540827912

Accessory(ies)

CORE
KIT ADAPT
FIXATION TACTIKKA®
SHELL L

Related product(s)

VERTEX®
VERTEX® VENT
STRATO
STRATO VENT