


705-1241

Mech Dial Ind Set


Specification: Dial Indicator 0-25mm

Resolution: 0.01mm

Accuracy: $\pm 0.03\text{mm}$

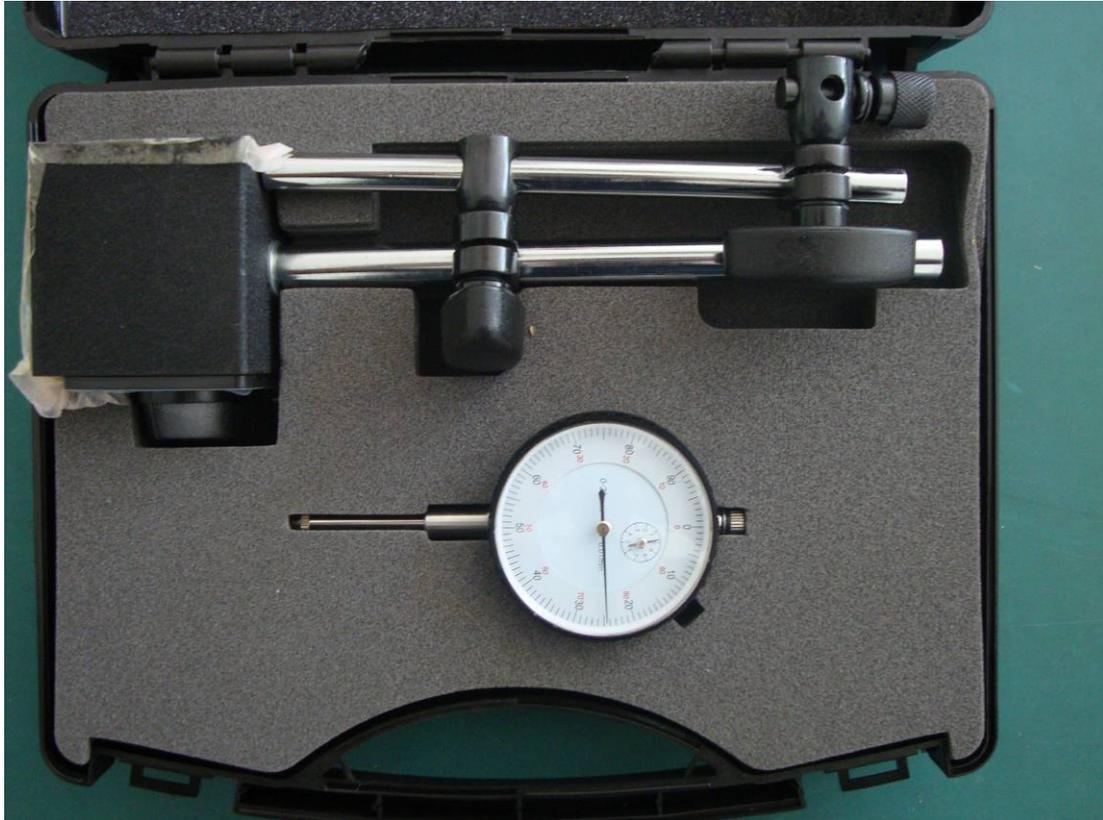

A	B	C	D	E	F	G	H	J
37.5	80.5	Ø58	16.3	19.4	17.5	34	Ø53.5	8.4

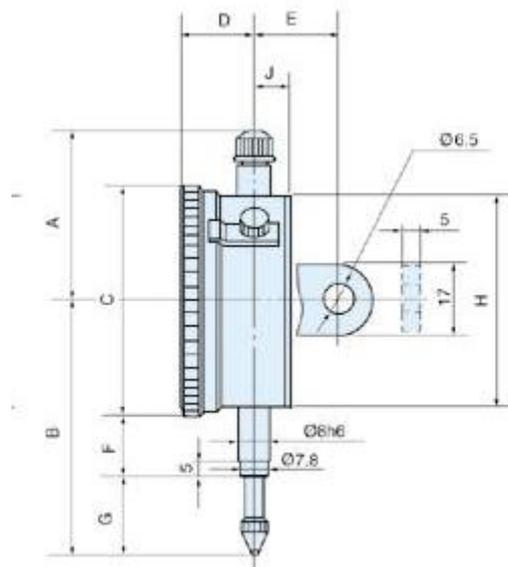

MAGNETIC INDICATION STAND

- Basic style
- Magnetic base with On/Off switch
- Clamp hole : 8 & 6.5 mm (optional: hole 3/8" & 5/32")
- For dial indicators with lug back or plain back
- Main stem : $\phi 12 \times 176$ mm
- Branch stem : $\phi 10 \times 160$ mm
- Tapped hole : M8 x 1.25 mm
- Weight : 1.4 kg

Magnetic force	Base(L x W x H)
60 kg	58 x 50 x 55

