
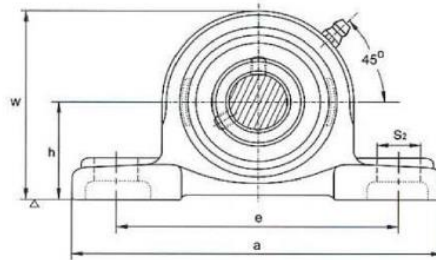


## 2 Bolt Pillow Block Medium Series – Metric

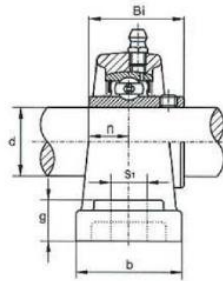

RS Article no.	Bearing unit No.	Shaft Dia.	Dimension (mm)										Bolt used	Bearing No.	Housing No.	Weight (kg)
		d (mm)	h	a	e	b	s <sub>2</sub>	s <sub>1</sub>	g	w	Bi	n	(mm)			
7509030	UCPX05	25	44.4	159	119	51	20	17	18	85	38.1	15.9	M14	UC X05	PX05	1.5
7509034	UCPX06	30	47.6	175	127	57	20	17	20	94	42.9	17.5	M14	UC X06	PX06	2.0
7509043	UCPX07	35	54.0	203	144	57	25	17	22	105	49.2	19.0	M14	UC X07	PX07	2.7
7509046	UCPX08	40	58.7	222	156	67	27	20	26	113	49.2	19.0	M16	UC X08	PX08	3.5
7509040	UCPX09	45	58.7	222	156	67	27	20	26	116	51.6	19.0	M16	UC X09	PX09	3.6
7509059	UCPX10	50	63.5	241	171	73	30	20	27	126	55.6	22.2	M16	UC X10	PX10	4.4
7509052	UCPX11	55	69.8	260	184	79	30	25	30	139	65.1	25.4	M20	UC X11	PX11	6.3
7509056	UCPX12	60	76.2	286	203	83	30	25	32	152	65.1	25.4	M20	UC X12	PX12	7.4
7509065	UCPX13	65	76.2	286	203	83	30	25	32	154	74.6	30.2	M20	UC X13	PX13	7.7
7509068	UCPX14	70	88.9	330	229	89	40	27	35	171	77.8	33.3	M22	UC X14	PX14	10.6