


METAL SAFETY QUICK COUPLINGS - CSM 11



Tapered male thread twin coupler

Profile : ISO 6150C

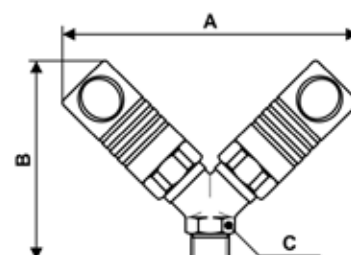

Min / Max operating pressure	Flow rate at 6 bar	ID passage (mm)	Min. / Max temperature
2 / 16 bar	4120 (l/min)	11 mm	-15 / 70 °C

Part number	Male thread	Dim. A (mm)	Dim. B (mm)	Dim. C (mm)
CSM 118153	R1/2	173	115	25
CSM 118154	R3/4	183	150	32