



Current transformers
 DM4TA3000

Product designation

Product type designation

Auxiliary supply U_s

Operational frequency

min	Hz	50
max	Hz	60

Current inputs

Primary current I_{pn} (/5) A 3000

Secondary output current A 5

Overload withstand I_{pn} % 120

Burden

cl. 0.5	VA	20
cl. 1	VA	25

Insulations

Rated insulation voltage U_i IEC/EN V 720

IEC rated short-time thermal current I_{th} I_{th} for s 40...60

IEC rated dynamic current I_{dyn} I_{th} for s 2.5

Insulation dry type Class E

Mechanical features

Terminals type Screw

Fixing Screw fixing

Weight g 3500

Ambient conditions

Temperature

Operating temperature

min	°C	-25
max	°C	+50


Storage temperature

min	°C	-40
max	°C	+80

Relative humidity % 90

Protection degree IP30

Dimensions

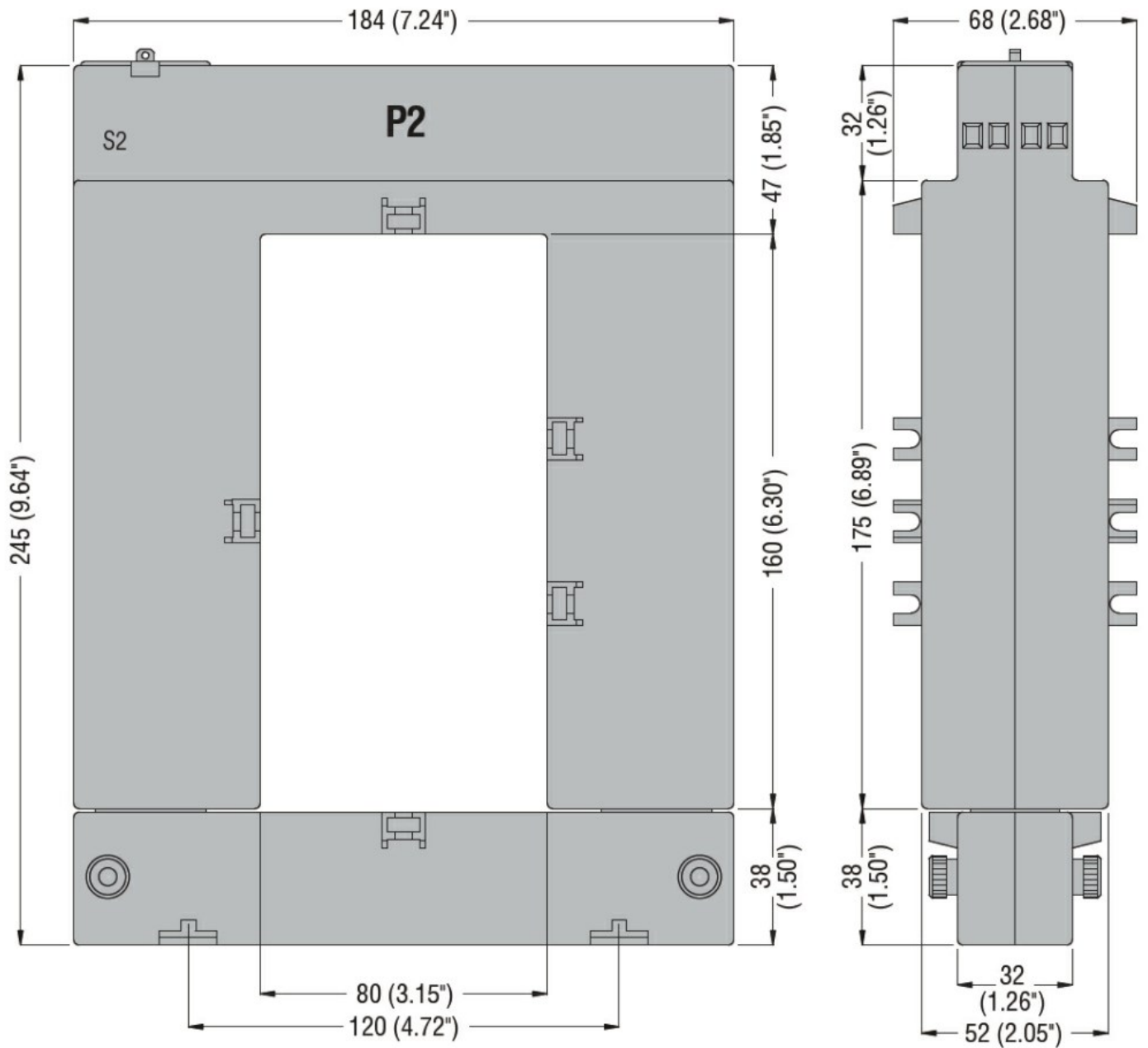

Certifications and compliance

Compliance

IEC/EN 60044-1

Certificates

EAC

GOST

ETIM classification

ETIM 8.0

EC002048 -
 Current
 transformer