


Plateswitches

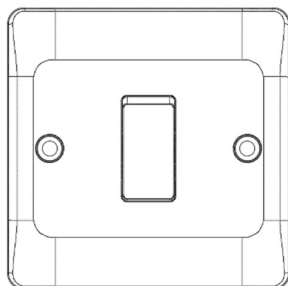

Description

This uniquely shaped range of 10A light switches is easy to install, has clear white terminal markings and is supplied in individual protective polybags suitable for display.

This range of plateswitches do not have to be de-rated for fluorescent loads and can be used by controlling lighting, door releases and bells.

Features

- Contemporary designed profile
- Concave rockers
- Only one size 4mm screwdriver needed
- Terminals have clear bold terminal markings
- Terminals have large lead-ins
- Range can be expanded using Gridswitch range
- 25-year guarantee

Range

1g 2w 10A	VP1203
2g 2w 10A	VP1204
3g 2w 10A	VP1205
4g 2w 10A	VP1244
6g 2w 10A	VP1245
Intermediate 10A	VP1246
3 pole fan isolator 10A	VP1247
Push to make/break 2w 'press'	VP1249
Push to make/break 2w – bell symbol	VP1249B

Technical Specification

Voltage rating	250Vac
Current Rating	10A
	X Rated
Contact gap	3mm
Front plate material	Urea formaldehyde

Urea flammability classification UL94 grade V-0

No user serviceable parts

Back Boxes

Minimum recommended depth

	Flush 25mm	Dry lining 35mm	Surface 25mm
1-3g	DB152	DB2540	VP1220/E
4-6g	DB163	DB2541	VP1223

Standards

- BS 60669-1

Terminal Capacity

	1mm ²	1.5mm ²	2.5mm ²	4mm ²
L	5	4	2	1