


Product datasheet

Specifications

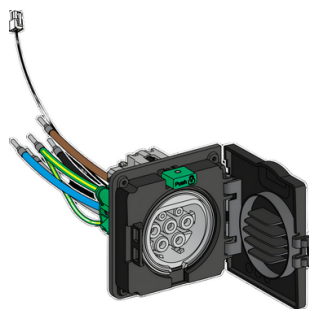

T2S socket-outlet subassembly 3- Ph IEC - Wallbox spare part

Local distributor code:
408708030

EVP1HSM43

EAN Code: 3606485435619

Main

Range	EVlink
Product or component type	Socket-outlet
Socket-outlet type	T2 with shutter
Poles description	3P + N
[Us] rated supply voltage	380...415 V AC 50/60 Hz
Maximum supply current	32 A
Earthing system	Compatible TT Compatible IT with additional isolation transformer on the power supply Compatible TN
Nominal output power	22 W 32 A
Range compatibility	EVlink EVlink Wallbox EVH2 charging station

Complementary

Material	Plastic
Product certifications	CE
Height	110 mm
Width	110 mm
Depth	90 mm

Environment

IP degree of protection	IP54 conforming to IEC 60529
IK degree of protection	IK10 conforming to IEC 62262
Ambient air temperature for operation	-30...50 °C
Ambient air temperature for storage	-40...80 °C
Relative humidity	5...95 %

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	15.000 cm
Package 1 Width	15.000 cm
Package 1 Length	40.000 cm
Package 1 Weight	621.000 g

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Logistical informations

Country of origin	FR
-------------------	----

Contractual warranty

Warranty	18 months
----------	-----------



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Use Better

Materials and Substances	
EU RoHS Directive	Compliant with Exemptions