


## Deep groove ball bearings, single row, seal on both sides

Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
30	62	16	20,3	11,2	0,475	-	7500	0,20	6206-2RS1 *

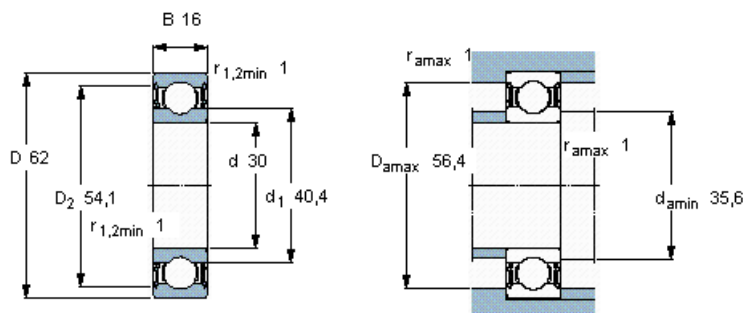

### Calculation factors

$k_r$  0,025

$f_0$  14