




Data sheet

- STRAIGHT SMA JACK - N PLUG ADAPTER

RS stock No: 5463068

NO	DESCRIPTION	DATE
△	BACKGROUND FORMAT UPDATED	07.16.02'
△	BACKGROUND FORMAT UPDATED	10.01.08'
△	DEL. 6.5	06.10.10'
△	WORKING VOLTAGE	01.09.13'
△	DEL. PROOF VOLTAGE	

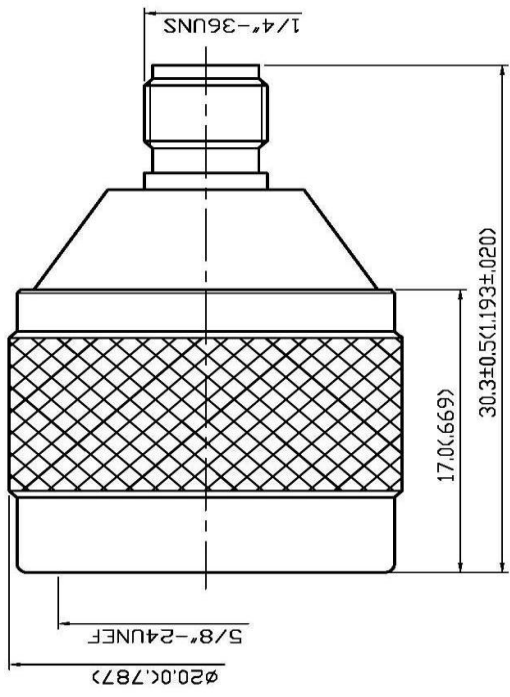

- 1.0 ELECTRICAL
 - 1.1 FREQUENCY RANGE: DC-11 GHz
 - 1.2 NOMINAL IMPEDANCE: 50 OHM
 - 1.3 VOLTAGE RATING: 500 VOLTS MAX. **A**
 - 1.4 VSWR: 1.3 MAX.
- 2.0 MATERIALS
 - 2.1 BODIES: BRASS PER JIS-C3804
 - 2.2 CENTER CONTACT: BERYLLIUM COPPER PER ASTM B198 UNS C17300
 - 2.3 INSULATION: TEFLON PER ASTM D1467 AND ASTM D1710
- 3.0 FINISHES AND OTHERS
 - 3.1. SEE BELOW TABLE FOR DETAILS.
- 4.0 MECHANICAL
 - 4.1 INTERFACE IN ACCORDANCE WITH: MIL-STD-348A
- 5.0 ENVIRONMENTAL
 - 5.1 OPERATING TEMPERATURE RANGE: -65° C TO +165° C

APPROVED by _____ DATE: _____

NO	DESCRIPTION	MATERIAL	Q'TY	FINISH
7	INSULATION	TEFLON	1	NONE
6	BODY II	BRASS	1	NICKEL 100μ" MIN.
5	CENTER CONTACT	BERYLLIUM COPPER	1	GOLD
4	WASHER	BRASS	1	NONE
3	BODY I	BRASS	1	NICKEL 100μ" MIN.
2	GASKET	SILICONE	1	RED
1	SHELL	BRASS	1	NICKEL 100μ" MIN.

DESCRIPTION	TOLERANCE	TITLE	DATE	REV.
STRAIGHT SMA JACK - N PLUG ADAPTER	X ±0.2	19-34-2 T.G.N	11.01.95' 日	版 A-4
製造	XX ±0.1	ROHS COMPLIANT (500)	期	次
檢圖	.XXX ±0.05	DWG.NO. 19-0122		
認定	ANGLE ±5°	UNIT mm(n)		
Angela	比例 4:1	SCALE		