

VELCRO® Brand

Self-engaging Hook & Loop Tapes



HOOK & LOOP ON OPPOSITE SIDES • HOOK & LOOP ON THE SAME SIDE



METHODS OF ATTACHMENT



Pressure sensitive adhesives
(See VELCRO® Brand Adhesives Range)



 
Sewing




Mechanical



Heat or solvent activated adhesives
(See VELCRO® Brand Adhesives Range)




Welding

 

Mold-in

 FABRICATION



Slitting



Scored cut



Custom manufactured straps



Pre-cut



Mated



Complete product assembly




Die cut




Perforated


PRINTING

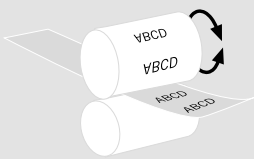


Flexography

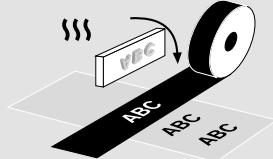

Hot stamping

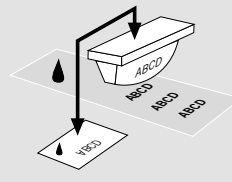

Pad printing

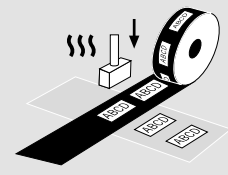

Heat transfer labels

PACKAGING



 
Rolls



Sealed bag



Bundling



Spools



Blister



Bulk



Shipping boxes



Folding boxes



Customised packaging



Labels

APPLICATIONS



APPAREL



CONSTRUCTION



MEDICAL



MILITARY &
GOVERNMENT



PACKAGING



PERSONAL
CARE



TRANSPORTATION



INDUSTRIAL











SPECIALTIES

Hook & Loop on Opposite Sides

A WIDE OFFERING OF BACK TO BACK TAPES WHERE HOOK AND LOOP ARE WOVEN, GLUED OR EXTRUDED TOGETHER AND GIVE DIFFERENT PERFORMANCE CHARACTERISTICS FROM HIGH CYCLE LIFE TO DISPOSABLE APPLICATIONS. BOTH HOOK & LOOP COMPONENTS OF THE CLOSURE ARE INTEGRATED IN A SINGLE PRODUCT



CHARACTERISTICS	FULL WIDTH HOOK COVERAGE				SINGLE HOOK LANE			
								
	Double Face 200	Back to Back (Hook & Loop)	ONE-WRAP® 29	BUNDLE TIE	FLEX-ZONE™ Hook 703	FLEX-ZONE™ Hook 796	FLEX-ZONE™ Hook 797	FLEX-ZONE™ Hook 898
BASE MATERIAL	Polyamide	Polyamide	Hook: Polypropylene Backing: Velour 3800 (polyamide)	Hook: Polypropylene Backing: Nonwoven 3310 (polyester)	Hook: Polypropylene Backing: Velour 3610 (polyamide)	Hook: Polypropylene Backing: Velour 3905 (polyamide)	Hook: Polypropylene Backing: Nonwoven (polyester)	Hook: Polypropylene Backing: Velour 3905 (polyamide)
CONSTRUCTION	Woven Hook & Loop woven together on opposite sides	Glued Woven Hook tape glued onto woven Loop tape	Extruded Plastic Hooks extruded onto back side of Loop material at full width		Extruded Single lane of Hooks extruded onto back side of Loop material			
CYCLE LIFE	Medium	High	Medium	Low	Medium/ Low	Medium/ Low	Medium/ Low	Medium/ Low
PEEL STRENGTH (AVERAGE)	2.6 N/cm	2 N/cm	2.1 N/cm	-	1.6 N/cm	0.9 N/cm	1.3 N/cm	1.1 N/cm
SHEAR STRENGTH (AVERAGE)	18 N/cm ²	10.3 N/cm ²	27 N/cm ²	Min. 7 N/cm ²	27 N/cm ²	18 N/cm ²	22 N/cm ²	20 N/cm ²
STANDARD COLOURS	Black, white	20 colours	Black, white, yellow, green, blue, red	Moss green	Hook: Black Backing: White	Hook: Black Backing: White, grey	Hook: Natural Backing: White	Hook: Natural Backing: White
STANDARD WIDTHS (mm)	25, 40	16, 20, 23, 25, 30, 38, 46, 50, 100, 125	10, 13, 16, 20, 25, 30, 38, 50, 107	10, 20	Overall: 200 Hook lane: 30	Overall: 200, 300 Hook lane: 15	Overall: 235 Hook lane: 10	Overall: 200 Hook lane: 12
STANDARD PUT-UPS	25 m rolls	25m rolls	25m rolls	25m rolls	50m rolls	51m rolls 91m rolls	60m rolls	75m rolls
EASY PEEL FEATURE	-	-	-	-	Yes	Yes	Yes	Yes
SOME APPLICATIONS	Medical: orthopaedics Transportation: accessories Specialties: bundling	Medical: orthopaedics Specialties: bundling	Materials handling Transportation: cable protection and handling Specialties: bundling, ideal for fibre optics	Specialties: agriculture and plant tie	Materials handling Transportation: cable protection and handling Specialties: bundling			
DISTINCTIVE CHARACTERISTICS	Temperature and chemical resistance Adhesive free, no delamination High softness and flexibility	Flexibility High cycle life	Hook-loop lamination without the use of adhesives Strong self-engaging	Hook-nonwoven lamination without the use of adhesives Disposable self-engaging	Disposable self-engaging			

NOTE: All the data indicated in this brochure are for reference only. Please, contact us for more detailed information.

Hook & Loop on the Same Side

WOVEN TAPES WHERE HOOK AND LOOP ARE WOVEN SIDE BY SIDE OR MIXED ON THE SAME FACE OF THE TAPE. ITS WOVEN TECHNOLOGY AND HIGH PROFILE SHAPE PROVIDE HIGH PERFORMANCE ON ENGAGEMENT VALUES. BOTH HOOK & LOOP COMPONENTS OF THE CLOSURE ARE INTEGRATED IN ONE PRODUCT




	HOOK & LOOP MIXED	HOOK & LOOP SIDE BY SIDE	
CHARACTERISTICS	OMNI-TAPE®	Side by Side Standard	Side by Side PS-14
BASE MATERIAL	Polyamide	Polyamide	Polyamide
CONSTRUCTION	Woven	Woven	
	Hook & Loop woven together and mixed	Hook & Loop woven side by side with a separation in between	
CYCLE LIFE	High	High	High
PEEL STRENGTH (AVERAGE)	1.22 N/cm	1.2 N/cm	1.2 N/cm
SHEAR STRENGTH (AVERAGE)	8.4 N/cm ²	13 N/cm ²	13 N/cm ²
STANDARD COLOURS	Black, white	Black, white	Black, white
STANDARD WIDTHS (mm)	20, 25, 50	50, 80	50
STANDARD PUT-UPS	25m rolls	25m rolls	25m rolls
SOME APPLICATIONS	Medical: orthopaedics Industrial: high quality apparel, leather jackets	Medical: plasters Specialties: furnishing covers	Specialties: cable guide, upholstery
DISTINCTIVE CHARACTERISTICS	Avoid scratching (loops protecting the hooks)	Closing system with a channel Protection High cycle life	

		TYPES OF CLOSURES	
		HOOK & LOOP ON OPPOSITE SIDES	HOOK & LOOP ON THE SAME SIDE
TECHNOLOGY	WOVEN	 Double face 200	 OMNI-TAPE® Side by Side
	GLUED	 Back to Back (Hook & Loop)	
	EXTRUDED	 ONE-WRAP® 29 / BUNDLE TIE	 FLEX-ZONE™

VELCRO® Brand
ONE-WRAP® Straps

PATENTED ONE-WRAP® & FLEX-ZONE™ TECHNOLOGIES PROVIDE THE ABILITY TO EXTRUDE HOOKS OR FLAT-ZONES CONTINUOUSLY ON A VARIETY OF LAMINATES AND SUBSTRATES

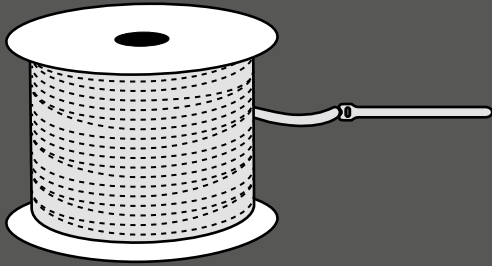


Pre-cut straps in spools

SIZE	STRAPS/ SPOOL	STRAP SHAPE
13x200 mm	750	13x200 7 mm
20x150 mm	1.000	20x150 13 mm
20x200 mm	750	20x200 13 mm
20x230 mm	650	20x230 13 mm
20x330 mm	450	20x330 13 mm
25x300 mm	500	25x300 17 mm
10x150 mm	1.200	10x150 10 mm
12x210 mm	700	12x210 12 mm

VELCRO® Brand
FLEX-ZONE™ Pieces




Pre-cut pieces

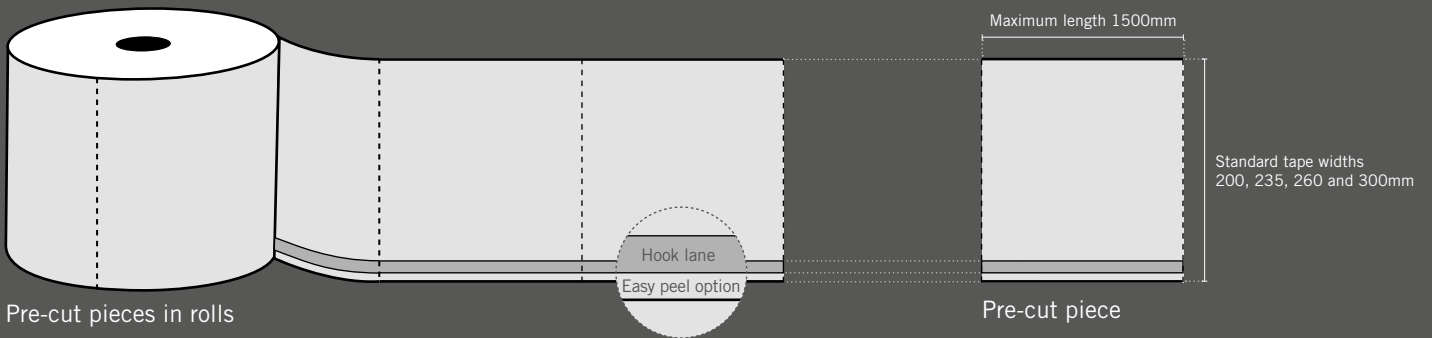


VELCRO® Brand
FLEX-ZONE™ Straps




Pre-cut straps

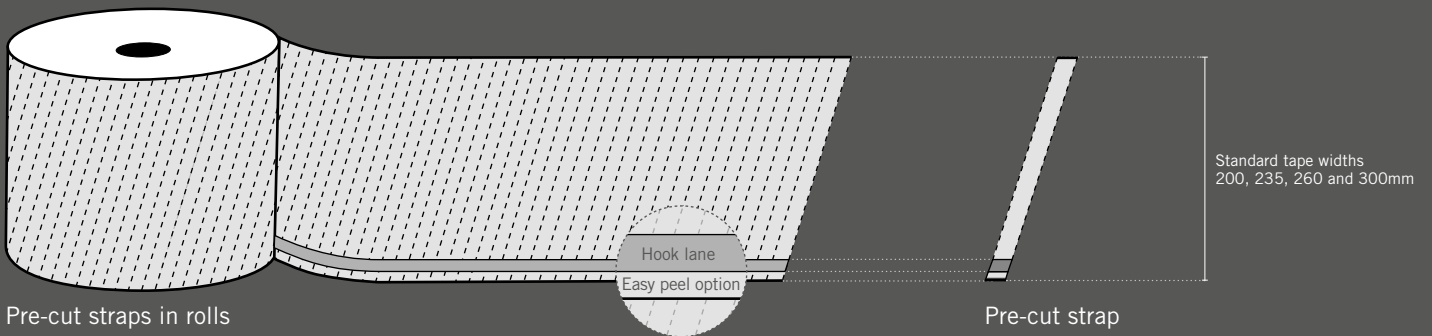


Customised length from 200 to 550 mm

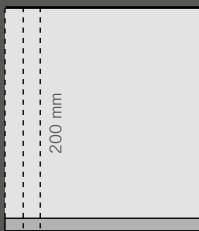

Minimum strap length

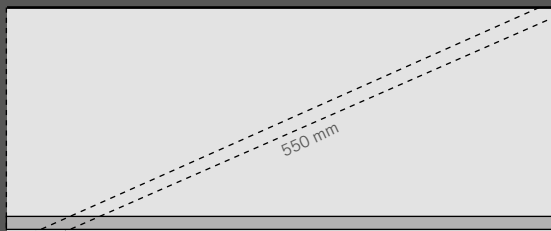

Maximum strap length

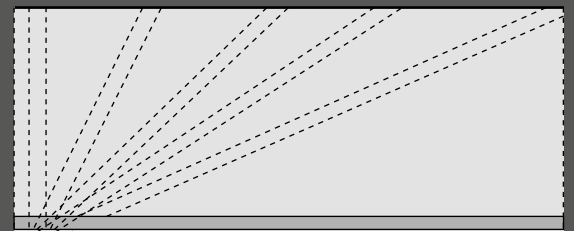

Some strap length options



Velcro Companies is a technology-driven, global organization providing fastening solutions that solve problems in simple, elegant and surprising ways for businesses and consumers around the world. We have a heritage of innovation spanning more than 50 years and own over 400 active patents and numerous trademarks, including the VELCRO® trademark, which is registered throughout the world. We develop and deliver solutions for customers through an integrated production and service system that includes manufacturing locations in the United States, Belgium, Canada, Mexico, Uruguay, Spain and China and sales offices around the world.

To buy genuine VELCRO® Brand products and to find out more about our company, visit Velcro.com



GLOBAL OFFICES

Global Services Office

Velcro Group Corporation
265 Franklin Street – 19th Floor
Boston – MA 02110
USA
Tel: (+1) 617 946 5501
Velcro.com

Global Consumer Office

VIL Ltd.
2 Kingdom Street, 6th Floor
Paddington
London – W2 6JP
United Kingdom
Tel: (+44) 203 580 4265
Velcro.com

NAM

USA

Velcro USA Inc.
Tel: (+1) 800 225 0180
marketing@velcro.com
Velcro.com

Canada

Velcro Canada Inc.
Tel: (+1) 800 683 5276
canada@velcro.com
Velcro.com

LATAM

Mexico

Velcro de México, S.A. de C.V.
Tlalnepantla de Baz,
Edo. de México
Tel: (+52) 55 5005 3300
infovdmex@velcro.com
Velcrodemexico.com

León, Gto
Tel: (+52) 477 980 0628
infovdmex@velcro.com
Velcrodemexico.com

Brazil

Velcro Brasil Ltda.
Campo Bom, RS
Tel: (+55) 51 3599 1483
infovbra@velcro.com
Velcro.com.br

Sumaré, SP
Tel: (+55) 11 3197 2576
infovbra@velcro.com
Velcro.com.br

Uruguay

Velcro Industrial
del Uruguay S.A.
Tel: (+598) 2288 0008
infovurg@velcro.com
Velcro.com

EMEA

Spain

Velcro Europe S.A.
Tel: (+34) 93 758 32 98
infovesa@velcro.com
Velcro.es

Germany

Velcro GmbH
Freiberg am Neckar
Tel: (+49) 7141 991 19-0
infovgmh@velcro.com
Velcro.de

Gronau
Tel: (+49) 2562 96 45-0
infovgmh@velcro.com
Velcro.de

France

Velcro Industries France S.A.S.
Tel: (+33) 1 34 38 78 88
infovif@velcro.com
Velcro.fr

Belgium

Alfatex N.V.
Tel: (+32) 9 386 12 18
infofobe@velcro.com
Velcro.be

Italy

Velcro Italia, S.R.L.
Tel: (+39) 039 62 70 01
infoveit@velcro.com
Velcro.it

UK

Velcro Ltd.
Tel: (+44) 1606 738 806
infov ltd@velcro.com
Velcro.co.uk

Poland

Alfatex Sp. z o.o.
Tel: (+48) 71 798 57 89
infovpl@velcro.com
Velcro.pl

APAC

Australia

Velcro Australia Pty. Ltd.
Tel: (+61) 3 9703 2466
infovaus@velcro.com
Velcro.com.au

China

Velcro China Fastening
Systems Company Limited
Tel: (+86) 21 6045 2090
(Shanghai Sales Office)
infovch@velcro.com
Velcro.com.cn

Hong Kong

Velcro Hong Kong Ltd.
Tel: (+852) 2570 3698
hksales@velcro.com
Velcro.com.hk

VELCRO COMPANIES AROUND THE WORLD

