




Table fans designed to offer a powerful and uniform distribution of air with a very quiet operation.

**Characteristics**

- 2 or 3 speed controller depending on the model.
- Adjustable fan position, that allows optimizing the distribution of air.
- Removable security grille.



Speed selector.

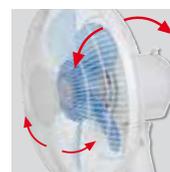

Adjusting fan position.

**TECHNICAL CHARACTERISTICS**

Model	Voltage 50Hz (V)	Nominal power (W)	Airflow* (m³/h)	Maximum air output speed (m/s)	Maximum sound power level (dB(A))	N° speeds	Fan position		Proof guard (detachable)	Motor with thermal protection	Carrying handle	Cable length (mm)	Colour	Weight (kg)	Dimensions (mm)		Wiring diagram** (n°)
							Inclinable	Fixed / oscillating							∅ Propeller	Height	
ARTIC-255 N	230	35	1.105/1.056	3,2	48	2	•	•	•	•	•	1.500	Grey	2,1	230	420	37
ARTIC-305 N	230	35	1.735/1.511/1.105	2,7	50	3	•	•	•	•	•	1.500	Grey	2,8	300	500	37
ARTIC-405 N	230	50	4.225/3.403/2.530	3,8	55	3	•	•	•	•	•	1.500	Grey	3,2	400	590	37

\* The indicated airflow include induced airflow.

\*\* See section of Wiring Diagrams.