


Product data sheet

Specifications

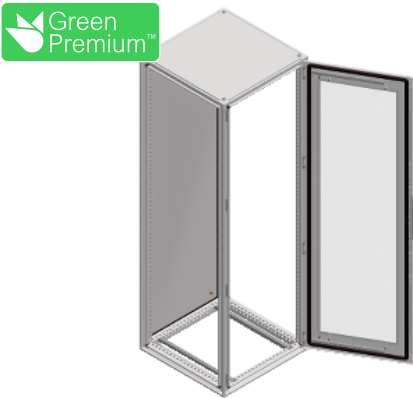

Spacial SF enclosure glazed door - assembled - 2000x600x500 mm

NSYSF20650T

Main

Range	Spacial
Extended range	Spacial SF
Application	Multi-purpose
Product or component type	Suitable enclosure
Enclosure nominal height	2000 mm
Enclosure nominal width	600 mm
Enclosure nominal depth	500 mm
Enclosure mounting	Floor-standing
Device composition	2 sliding rails 4 mounting plate bracket 1 structure 1 door 1 locking system with handle: door 1 rear panel 1 roof

Complementary

Structure type	Vertical uprights joined with top and bottom frames Perforated structure with a pitch of 25 mm Formed from a single section Panels and doors built into the structure
Door type	Glazed front
Number of doors	Front: 1 door(s)
Door opening side	Reversible (120 °)
Lock type	4 points lock, handle with 5 mm double bar insert front door
Mounting plate description	Without mounting plate
Type of gland plate	Without gland plate
Accessibility for operation	Front Sides of enclosure Rear
Removable parts	Door by screws hinge Rear panel by screws Roof by screws Mounting plate bracket by screws Sliding rail by screws
Material	Frame: galvanised steel Uprights: galvanised steel Door: Securit glass Door: sheet steel Panels: sheet steel

	Hinge: zamak Handle: polyamide 6 with 30 % fibre glass
Surface finish	Epoxy-polyester powder
Colour	Enclosure: grey (RAL 7035) Handle: black (RAL 9005)
Net weight	95.4 kg

Environment

Standards	IEC 62208
NEMA degree of protection	NEMA 3R/12
IP degree of protection	IP55 conforming to IEC 60529
IK degree of protection	IK08 conforming to IEC 62262

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	95.4 kg
Package 1 Height	213.0 cm
Package 1 width	64.5 cm
Package 1 Length	59.0 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------