

HyFlex[®]

ADVANCED MECHANICAL PROTECTION

70-205

Light weight Cut resistant style with Heat protection

Previously known as: Neptune[®] Kevlar[®]



Cut



Medium Duty

A great combination of superior cut resistance and contact heat protection

- Designed to provide superior mechanical strength in light to medium duty handling and production applications
- In addition to the high cut resistance, these gloves offer enhanced comfort and dexterity to the wearer
- Thanks to the Neptune[®] coating, the glove fibres repel liquids, avoiding damage to the Kevlar[®] strands and extending glove life
- The reinforced thumb welt increases abrasion resistance, also adding to the glove durability



Industries

- Automotive
- Machinery and Equipment
- Metal fabrication

Applications

- Assembling metal parts and components
- Body assembly
- Handling sharp or irregular metal pieces

HyFlex[®]

ADVANCED MECHANICAL PROTECTION

70-205

Light weight Cut resistant style with Heat protection

Previously known as: Neptune[®] Kevlar[®]

Key Features

- Ergonomic design provides comfort
- Kevlar provides Cut performance
- Neptune coating extends the working life protecting the Kevlar fibres and reeling Liquids


Vulcanization Chemical Accelerators

- Natural rubber proteins

Only a very small number of users may be sensitive to this ingredient(s) and hence may develop irritant and/or allergic contact reactions.

Performance Standards & Regulatory Compliance

REACH Compliant

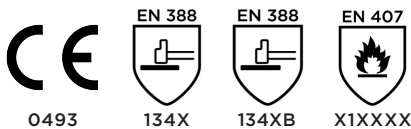

Technologies

Kevlar[®]

Specifications

BRAND STYLE	DESCRIPTION	Gauge	SIZE	LENGTH	PACKAGE
HyFlex [®] 70-205	Liner Material: Kevlar [®] Cuff Style: Knitwrist	13	7, 8, 9, 10	220-280 mm	• 12 pairs in a bag; 12 bags in a carton

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
Riverside Business Park
Blvd International, 55
1070 Brussels, Belgium
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

North America Region

Ansell Healthcare Products LLC
111 Wood Avenue South,
Suite 210
Iselin, NJ 08830, USA
T: +1 800 800 0444
F: +1 800 800 0445

Australia

Ansell Limited
Level 3,678 Victoria Street,
Richmond, Vic, 3121
Australia
T: +61 1800 337 041
F: +61 1800 803 578

Asia Pacific Region

Ansell Global Trading Center
(Malaysia) Sdn Bhd
Prima 6, Prima Avenue
Block 3512, Jalan Teknokrat 6
T: +603 8310 6688
F: +603 8310 6699

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
Blvd. Bernardo Quintana No. 7001-C,
Q7001 Torre II,
Suites 1304, 1305 y 1306,
Col. Centro Sur, c.p. 76079
Queretaro, Qro. Mexico
T: +52 442 248 1544 / 248 3133

Canada

Ansell Canada
105 Lauder
Cowansville, QC J2K 2K8
Canada
T: +1 800 363 8340
F: +1 800 267 3551

Ansell, [®] and [™] are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:
www.ansell.com/patentmarking © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.