


## FEATURES

- **Nylon Material:** Provides durability and resistance to wear and tear
- **22kg Tensile Strength:** Ensures strong and secure bundling of cables
- **300mm Length:** Suitable for a wide range of cable sizes and applications
- **UL 94 V-2 Fire Behaviour:** Offers flame retardant properties for added safety
- **RoHS Compliant:** Meets environmental and safety standards
- **4.8mm Width:** Offers a balance between flexibility and strength
- **Maximum Operating Temperature of 150°C:** Suitable for high-temperature environments

## RS PRO 300mm Nylon Cable Tie, 22kg Tensile Strength

RS Stock No: 656-011

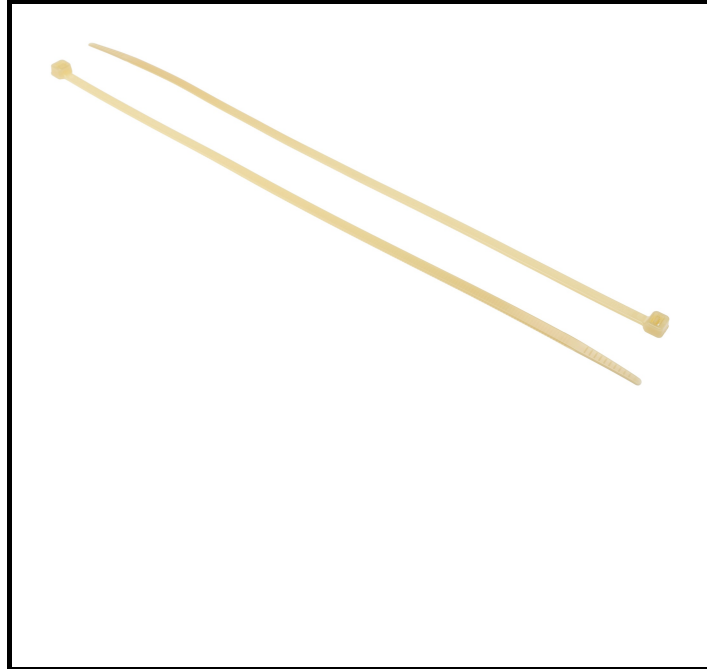

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

### Product Description

RS PRO offers a high-quality nylon cable tie designed for secure and efficient cable management. With a length of 300mm, this non-releasable cable tie is ideal for bundling cables and wires in various industrial and commercial settings. Its robust construction ensures reliable performance, making it a valuable addition to any toolkit.

### General Specifications

Colour	Light Brown
Product Type	Cable Tie
Sub Type	Non-Releasable
Tensile Strength	22 kg

### Protection Category

Fire Behaviour	UL 94 V-2
UV Resistant	No

### Mechanical Specifications

Length	300 mm
Material	Nylon
Maximum Bundle Diameter	83 mm
Width	4.8 mm

### Operation Environment Specifications

Maximum Operating Temperature	150 °C
-------------------------------	--------

### Approvals

Standards/Approvals	RoHS, UL94V-2
---------------------	---------------

