

# Housing - HC-B 24-SMLD-67/M1M25 - 1586950


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Box mounting base, with single locking latch, height 67 mm, with screw connection, 1x M25, with protective cover



## Key Commercial Data

Packing unit	10 pc
GTIN	 4 046356 427043
Weight per Piece (excluding packing)	500.0 g
Custom tariff number	85389099
Country of origin	Germany
Note	Made to Order (non-returnable)

## Technical data

### Dimensions

Height	67 mm
Width	57 mm
Length	144 mm
Wrench size, union nut	25 mm
External cable diameter	9 mm ... 18 mm

### Ambient conditions

Degree of protection of housing (IP)	IP65 (When plugged in)
	IP54 (mit geschlossenem Schutzdeckel)
Ambient temperature (operation)	-40 °C ... 125 °C

### General

Type	B24
Housing type	Box mounting bases
Locking type	With single locking latch
No. of cable outlets	1
Cable exit	Left (view of the opened single locking latch)

# Housing - HC-B 24-SMLD-67/M1M25 - 1586950

## Technical data

### General

Screw connection	with
Type of the screw connection	1x M25
Protective cover	Yes
Housing material	Aluminum die-cast
Housing surface material	Powder-coated, gray
Seal material	NBR
Cable gland material	Nickel-plated brass
Cable seal material	NBR
Material lock	Stainless steel, handle: PA
Material grip body interlock	PA
Material, protective cover	Polyamide

## Classifications

### eCl@ss

eCl@ss 4.0	272607xx
eCl@ss 4.1	27260701
eCl@ss 5.0	27143424
eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440202

### ETIM

ETIM 3.0	EC000437
ETIM 4.0	EC000437
ETIM 5.0	EC000437

### UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261502

## Approvals

### Approvals

Approvals

EAC

# Housing - HC-B 24-SMLD-67/M1M25 - 1586950

## Approvals

---

Ex Approvals

---

Approvals submitted

---

## Approval details

EAC
-----

## Accessories

Accessories

Full screw connection

Cable gland - HC-K-KV-M25(11-17) - 1690639



Plastic screw connection up to 5 bar, thread length: 8 mm, cable diameter: 11 - 17 mm, WAF 29, screw connection: M25

---

Cable gland - HC-M-KV-M25(11-16) - 1690574



Metal screw connection up to 5 bar, thread length: 7 mm, cable diameter: 11 - 16 mm, WAF 27, screw connection: M25

---

Cable gland - HC-M-KV-M25(14-21) - 1646007



Metal screw connection up to 5 bar, thread length: 7 mm, cable diameter: 14 - 21 mm, WAF 34, screw connection: M25

---

## Housing - HC-B 24-SMLD-67/M1M25 - 1586950

### Accessories

Cable gland - HC-M-KV-M25(1ASI) - 1584020



Metal screw connection for an AS-Interface flat-ribbon conductor, thread type M25

---

### Multiple screw connection

Cable gland - HC-M-KV-M25(1X10/1X11) - 1580228




Special cable screw connection M25, brass nickel-plated, grommet with 10 mm and 11 mm holes

---

### Drawings

Dimensional drawing

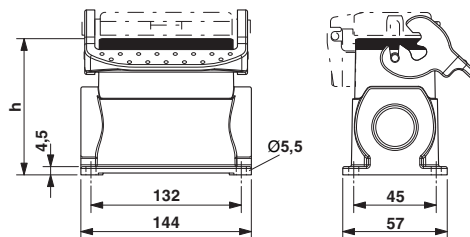

Dimensional drawing; h = 67 mm