

Smart filament bulb



DELTACO

SMART

PRODUCT DATA

Product category:	Smart filament bulb
Fitting:	E27
Shape:	G95
Wattage and lumen:	5.5 W, 470 lm
Colour:	White CCT
Colour temperature:	1800-6500 K
Dimmable:	Yes (with app)
Lifetime:	15000 h
Input voltage:	220-240 V
WiFi frequency:	2.4 GHz
Network protocol:	IEEE802.11 b/g/n
Compatibility:	APP: DELTACOSMARTHOME, Amazon Alexa & Google Home Voice Assistance
Working temperature:	-20°C to 40°C
Package contents:	Smart bulb and manual.

Dimmable
Amber glass
Control with app
Adjustable colour temperature




LOGISTICS DATA

Article number:	SH-LFE27G95
Brand:	DELTACO
EAN code:	7333048043863
Country of origin:	China
Custom tariff number:	85414010
Master carton packing unit:	N/A
Master carton gross weight:	N/A
Master carton dimensions:	N/A
Package type:	Box
Package weight:	N/A
Package dimensions:	N/A



Drawing

on the top side

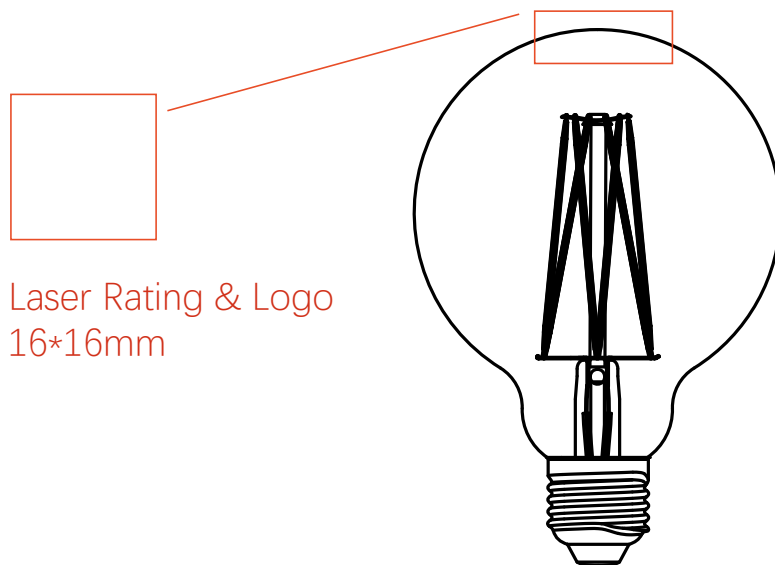

Laser Rating & Logo
16*16mm