

## R.LA 1/4" LONG-REACH METRIC 6-POINT SOCKETS




### Standards :


NF ISO 2725-1, NF ISO 1711-1, ISO 2725-1, ISO 1711-1, DIN 3124, ASME B107.5


### Description :

- OGV® profile: more powerful tightening, preserves fasteners.
- Long-reach sockets for long recess or thread access.
- Available as rack set Ref RL.40E (3.2 --> 9 mm) and Ref RL.41E (10 --> 14 mm).
- Finish: bright chrome.

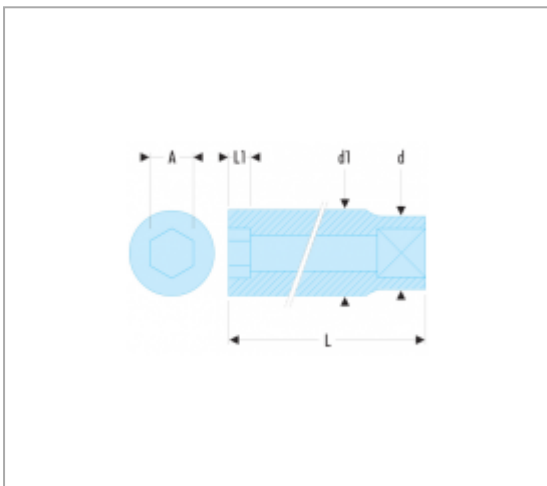

### References :

	A [MM]	D [MM]	D1 [MM]	L [MM]	L1 [MM]	HEX SIZE [MM]	[KG]
R.3.2LA	3,2	12,0	5,80	50,5	1,8	6	0.018
R.10LA	10,0	14,3	14,30	50,5	7,9	6	0.041
R.11LA	11,0	16,0	16,00	50,5	7,9	6	0.054
R.12LA	12,0	16,8	16,80	50,5	8,4	6	0.050
R.13LA	13,0	18,2	18,20	50,5	8,4	6	0.059
R.14LA	14,0	19,2	19,20	50,5	10,2	6	0.068
R.4LA	4,0	12,0	6,80	50,5	2,0	6	0.018
R.5.5LA	5,5	12,0	8,10	50,5	3,0	6	0.018

	A [MM]	D [MM]	D1 [MM]	L [MM]	L1 [MM]	HEX SIZE [MM]	[KG]
R.5LA	5,0	12,0	8,10	50,5	2,3	6	0.018
R.6LA	6,0	12,0	9,40	50,5	5,6	6	0.018
R.7LA	7,0	12,0	10,90	50,5	7,1	6	0.027
R.8LA	8,0	12,0	12,00	50,5	7,9	6	0.027
R.9LA	9,0	12,8	12,80	50,5	7,9	6	0.032