


drylin® R linear slide bearing RJUM-01

RJUM-01-20

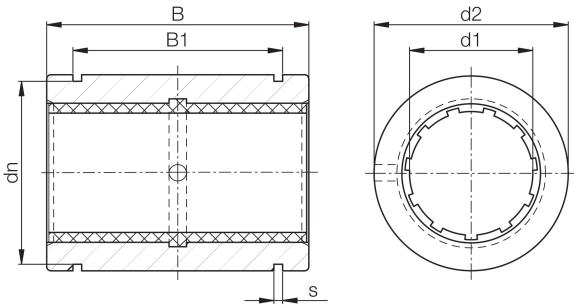

drylin® R linear slide bearing RJUM-01

- Secured by circlips
- closed anodised aluminium adapter
- Material of the liner: iglidur® J

Part number	RJUM-01-20
Ø d1	20 mm
Ø d2	32 mm
B	45 mm
B1	31.2 mm
s	1.6 mm
Ø dn	29.6 mm

Product description

Introducing the drylin R linear slide bearing RJUM-01, a reliable solution for smooth linear motion. This bearing features a secure circlip design and an enclosed anodised aluminium adapter for enhanced durability. The liner is made from high-quality iglidur J material, ensuring long-lasting performance. Ideal for various applications, the RJUM-01 provides excellent support and stability. Discover the perfect fit for your needs with this versatile linear slide bearing.

Requirements

Mould-resistant according to DIN EN ISO 846 Procedure A	No
---	----

Manufacturing and installation tolerances

d1 tolerance	+0.030 +0.091 mm
d2 tolerance	h7
B tolerance	h10
s tolerance	H10
dn tolerance	h10



Dimensions

Ø d1	20 mm
Ø d2	32 mm
B	45 mm
B1	31.2 mm
s	1.6 mm
Ø dn	29.6 mm

General properties

Sliding element material	iglidur® J
Fmax. Dynamic, P = 5 Mpa	2250 N
Fmax. Static, P = 35 Mpa	15750 N

Certificates and standards



Additional information and diagrams

