



**Series POS & POO**  
- open body with and without centre bars -  
*If you need all Insulator Dimension pls. ask for customer drawing!*

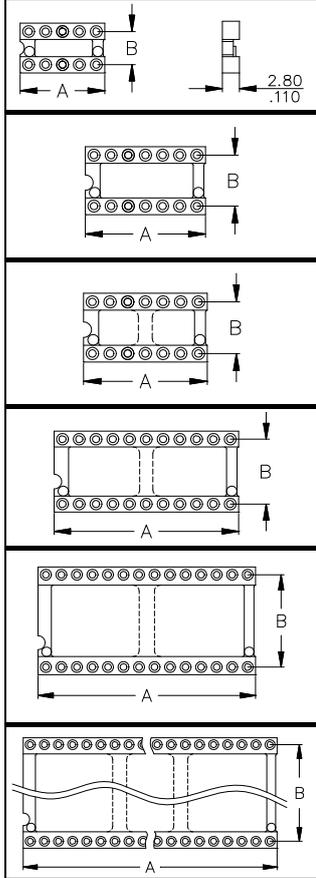

**POS sockets in 7,62mm/.300" DIP spacing are either supplied with or without bars in the centre depending on plastic wafer availability. If you need sockets without centre bars, then please always order with POO instead of POS.**


Pin	Dimension		Available Pinouts of Series		
	"A"	"B"	POS	POO	PCL
10	12,60	5,08 .200"	-	-	<b>-210-</b>
6	7,60	7,62 .300"	<b>-306-</b>	-	-
8	10,10		<b>-308-</b>	-	-
10	12,60		<b>-310-</b>	-	-
14	17,70		<b>-314-</b>	<b>-314-</b>	<b>-314-</b>
16	20,30		<b>-316-</b>	<b>-316-</b>	<b>-316-</b>
18	22,80		<b>-318-</b>	<b>-318-</b>	<b>-318-</b>
20	25,30	7,62 .300"	<b>-320-</b>	<b>-320-</b>	<b>-320-</b>
22	27,80		on request	on request	-
24	30,40		<b>-324-</b>	<b>-324-</b>	-
28	35,50		<b>-328-</b>	<b>-328-</b>	-
16	20,32	10,16 .400"	on request	on request	on request
22	27,80		on request	on request	on request
24	30,60		on request	on request	on request
24	30,50	15,24 .600"	<b>-624-</b>	<b>-624-</b>	on request
28	35,50		<b>-628-</b>	<b>-628-</b>	<b>-628-</b>
32	40,60		<b>-632-</b>	<b>-632-</b>	<b>-632-</b>
36	45,70		<b>-636-</b>	on request	-
40	50,80		<b>-640-</b>	<b>-640-</b>	<b>-640-</b>
48	60,96		<b>-648-</b>	on request	on request
64	81,26	22,86 .900"	on request	-	-

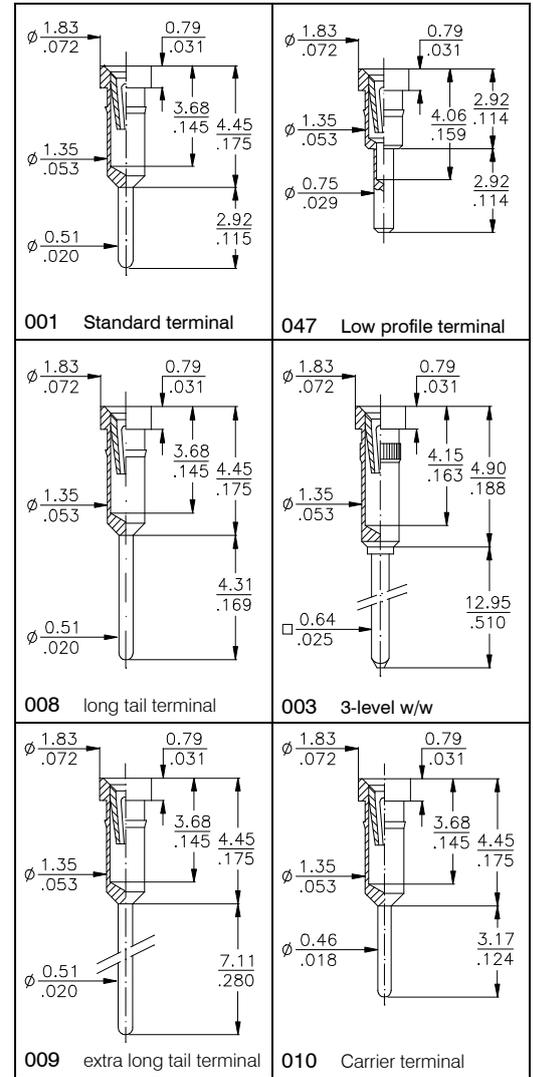

**Specifications**  
PBT and high temp plastic depending on type.  
See page 49 of this catalogue and contact factory for more details.

**Insulator body**  
POS series = open insulator - see drawings above  
POO series = open insulator w/o centre bars  
PCL series = closed insulator body


**Terminals**  
The POS, POO and PCL series are available with many different terminal styles. The most common terminal styles are shown on the right hand side of this page. Many other additional terminals can be found at the end of this catalogue. Custom design terminals are available on request.

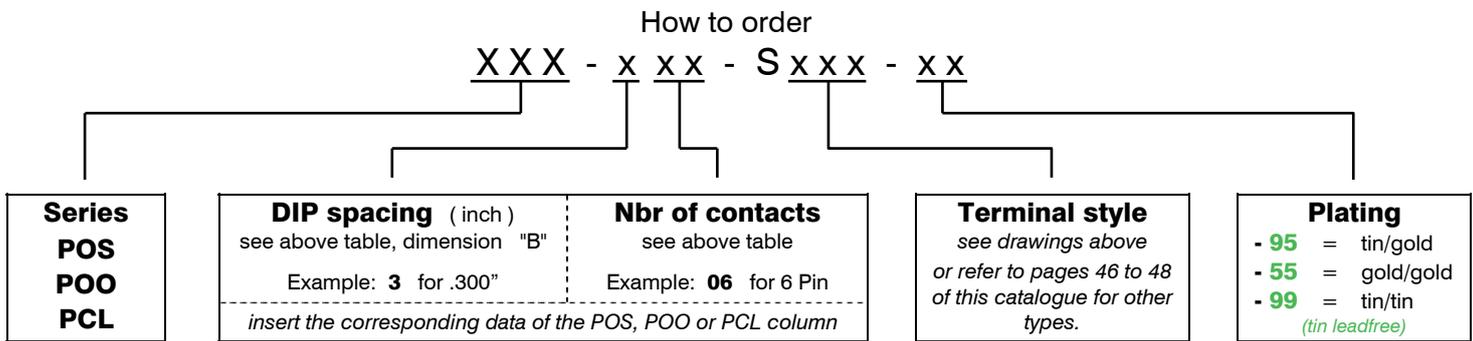




**Board Stacker Terminals**

<p><b>079</b></p>	<p><b>623</b></p>	<p><b>062</b></p>
<p><b>060</b></p>	<p><b>063</b></p>	<p><b>080</b></p>
<p><b>084</b></p>	<p><b>085</b></p>	<p><b>088</b></p>
<p><b>065</b></p>	<p><b>Many other terminals and custom specific terminal styles are available on request, or refer to the pages 46 to 48 of this catalogue.</b></p>	

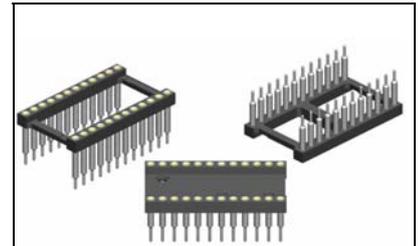


**Application Examples**

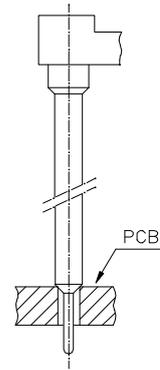

**Possible Terminals:**

060; 062; 063; 065; 079  
080; 084; 085; 088; 623

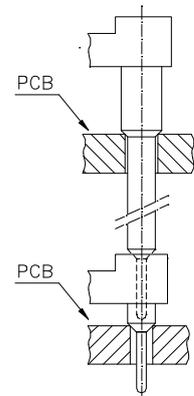

**Possible Terminals:**

060; 062; 063; 079; 623

**Specifications**

See page 49 of this catalogue

How to order


XXX - x xx - S xxx - xx

<p><b>Series</b> POS POO PCL see page 14</p>	<p><b>DIP spacing</b> in inch refer to table, dimension "B" on page 14  insert the corresponding data of the POS, POO or PCL column</p>	<p><b>Nbr of contacts</b> refer to table on page 14</p>	<p><b>Terminal style</b> see drawings above or refer to pages 46 to 48 of this catalogue for other types.</p>	<p><b>Plating</b> - 95 = tin/gold (tin leadfree) other on request</p>
--	---	---	---	---




**Board to Board Terminals**

<p>077</p>	<p>057</p>	<p>037</p>
<p>058</p>	<p>059</p>	<p>056</p>
<p>542</p>	<p>038</p>	<p>353</p>
<p>036</p>	<p><b>Many other terminals and custom specific terminal styles are available on request, or refer to the pages 46 to 48 of this catalogue.</b></p>	

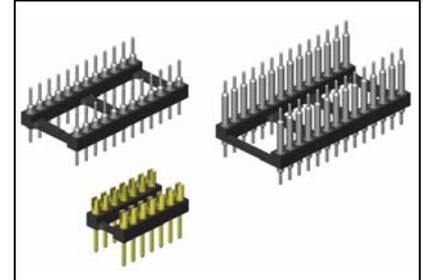


**Application Examples**

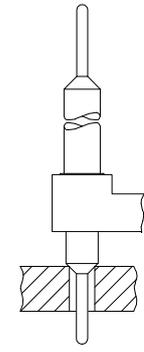

**Possible Terminals:**

- 037; 056; 057; 058; 059; 077
- 220; 221; 542; 543; 544; 562
- 770

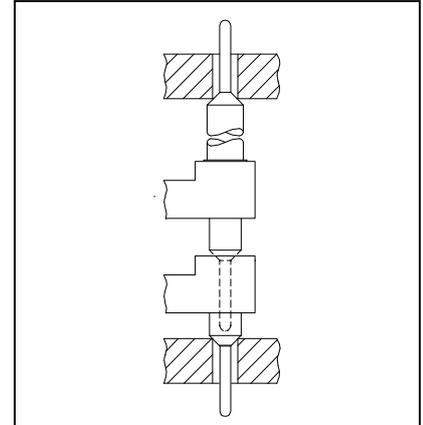

**Possible Terminals:**

- 037; 056; 057; 058; 059
- 077; 542; 544; 562; 770

**Specifications**

See page 49 of this catalogue

**How to order**

**XXX - xxx - Sxxx - xx**

<p><b>Series</b> <b>POS</b> <b>PCL</b> see page 14</p>	<p><b>DIP spacing</b> in inch refer to table, dimension "B" on page 14</p>	<p><b>Nbr of contacts</b> refer to table on page 14</p>	<p><b>Terminal style</b> see drawings above or refer to pages 46 to 48 of this catalogue for other types.</p>	<p><b>Plating</b> - 55 = gold - 99 = tin (tin leadfree)</p>
--	--	---	---	---