
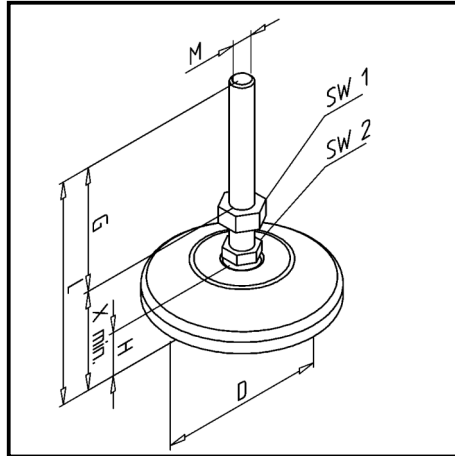


FOOT M08 D45 L=72

Article Nr. 21.1871/0

[See the product on the website →](#)

[Download CAD Files →](#)

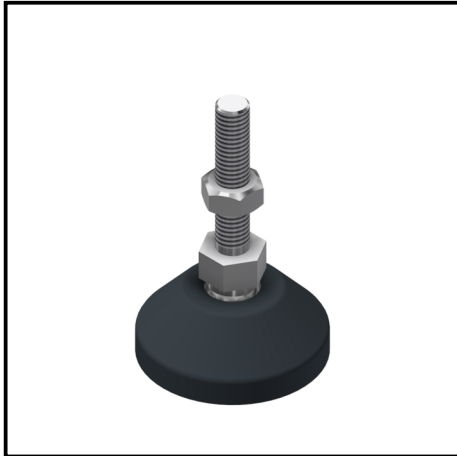

TECHN. DATA / ITEMS SUPPLIED

- Plate PA, grey
- Anti-slip license NBR, black
- Spindle steel, galvanized
- Lock nut steel, galvanized
- Angular compensation up to 15°
- D = 45 mm
H = 20 mm
Load capacity max. 500 kg
- Dimension G = 33.5 mm
Dimension X = 38.5 mm
SW1 = 13 mm
SW2 = 14 mm
Dimension L = 72,5 mm
- Weight = 0.060 kg/piece

APPLICATIONS

- Height adjustable constructions of all kinds
- Protective equipment, tables, showcases
- Conveyors, system workstations

ASSEMBLY

- Direct in central drilling of the profiles
- For threads larger than M12, the hinged feet must be mounted in conjunction with the connection plate
- For profiles 45 x 90 und 90 x 90 a base and transport plate is required, if the feet are to be positioned centrally.