

 

intermediate pressure regulator plate

LR-ZP-A-D-3

Part number: 35971



For ISO valves.

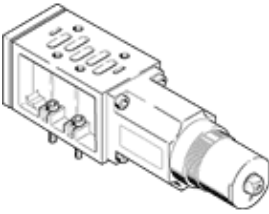

Data sheet

Feature	Value
Based on the standard	ISO 5599-1
Integrated function	Pressure regulator
Design structure	Piston
Pressure regulation range	0.5 ... 12 bar
Inlet pressure 1	≤ 14 bar
Authorisation	UL - Recognized (OL)
Product weight	1,220 g
Materials note	Contains PWIS substances Conforms to RoHS
Material seals	NBR
Material housing	Aluminium die cast Steel