


Grey Elastic Rubber Trolley Wheel 100mm, 150kg

Elastic Rubber-tyred wheel

PRODUCT

Article number 58-416-100R12

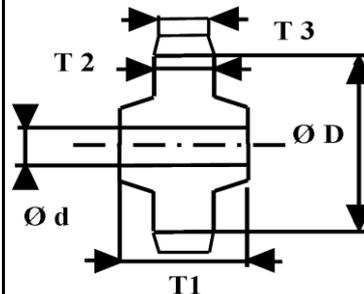

Product Details

Wheel Rim : very thick black polyamide.
 Tyre : solid, grey bonded elastic rubber tyre, non marking.
 Hub : symmetrical, roller bearing.

Specifications

Wheel Diameter - ØD ± 1%	100 mm
Hub Type	Roller Bearing
Hub Length T1	45 mm ±1
Width of Tread T2	36 mm ±1
Width of Tread-on floor T3	36 mm ±1
Axle Hole Ø d	Ø 12 mm
Hardness of tread A ±4	A 70 Shore
Load capacity	150 Kg
Temperature	-20 / +60 °C
Weight	0,29 Kg

TECHNICAL DATA

Applications :

Sensitive materials handling on uneven surfaces.
 Resilient with a low starting effort.
 Does not leave scratches or other marks on surfaces.
 Reduces shock and vibration.
 Quiet in use and high wear resistance.
 Suitable for industrial floors and also all interior floors.