

Datasheet

RS Pro Drill Vice

RS Stock No: 463-7296




Specifications:

- Small drill vice for use in drilling and light milling operations
- Effectively grips round, square, thin and irregular sections
- The jaws are made of hardened steel and the base cast iron
- Handle is mounted on ball bearings to give more gripping power, smooth action and long life
- Jaw width: 83mm, Jaw height capacity: 31mm, Jaw height from base: 50mm
- Max capacity at top of jaws: 60mm
- Max capacity between main faces of jaws: 55mm
- Max width of base: 150mm
- Overall length with jaws closed: 260mm
- Overall length with jaws fully opened: 320mm
- Clamping slot width: 11.5mm (M10 clamping bolts recommended)

Order Code	Manufacturers Code	Description
463-7296	52-810-085	Drill Vice

Datasheet RS Pro Drill Vice

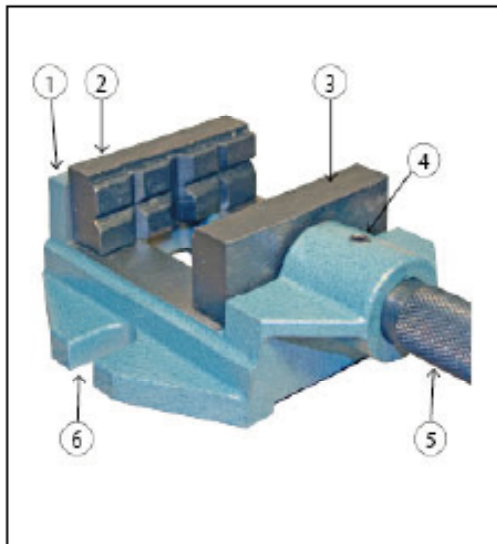

- 1 Cast Iron Vice Body
- 2 Fixed Vice Jaw, manufactured from hardened steel, complete with one horizontal and three vertical vee grooves.
- 3 Sliding Vice jaw, manufactured from hardened steel
- 4 Lubrication Port for handle bearing
- 5 Vice Handle
- 6 Clamping Slots (x2): 11.5mm wide, suitable for M10 clamping bolts

Note: When lubricating the handle bearing, remove the grub screw and apply a general bearing grease to the mechanism. Replace the grub screw making sure it does not clamp down on the bearing balls which will cause the handle to lock