



## U.232 - 2-leg sliding-leg pullers



### Description:

- Versatile: conversion possible in inside or outside grip with the same leg.
- Safety: - Stops to prevent legs from falling. - Under pressure, the legs are set to overhang to avoid sliding.

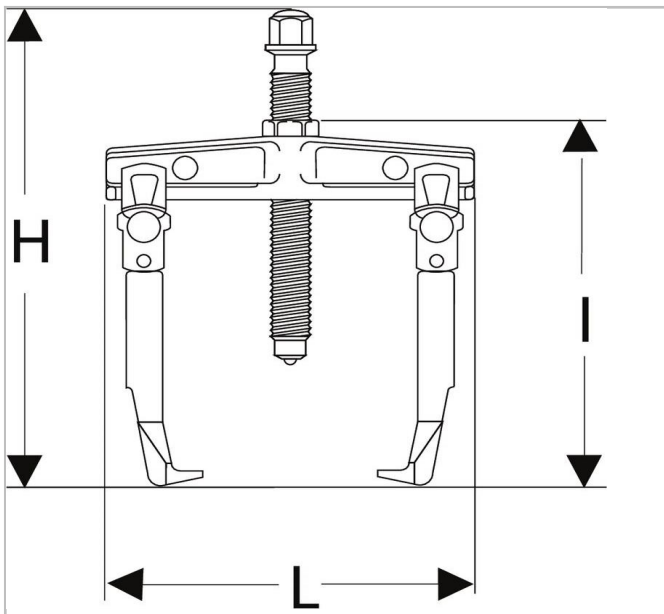

	Depth Maxi [mm]	Length L [mm]	Height H [mm]	Length [mm]	Hex Size [mm]	Screw Size ["]	Screw Size Multi [mm]	Tonnes []	t []	Weight [Kg]
<b>U.232-130</b>	100.0	186.0	182.0	155.0	21.0	U.35SE1	17.0	3.0	30.0	1.0
<b>U.232-160</b>	145.0	247.0	283.0	233.0	27.0	U.53S2A07	17.0	4.0	40.0	2.8
<b>U.232-210</b>	145.0	297.0	283.0	233.0	27.0	U.53S2A07	17.0	4.0	40.0	3.0
<b>U.232-270</b>	190.0	379.0	345.0	303.0	36.0	U.53S3-07	32.0	5.0	50.0	7.5
<b>U.232-340</b>	190.0	449.0	345.0	303.0	36.0	U.53S3-07	36.0	5.0	50.0	8.2
<b>U.232-65</b>	65.0	115.0	133.0	105.0	16.0	U.35P01	13.0	1.5	15.0	0.4
<b>U.232-90</b>	100.0	146.0	182.0	155.0	21.0	U.35SE1	17.0	3.0	30.0	0.9