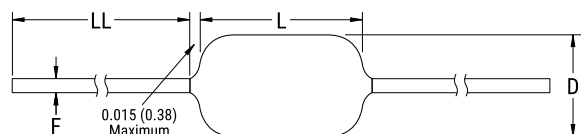


AxiMax 400 Auto X8L HT150C, Ceramic, 2.2 uF, 10%, 25 VDC, X8L, AxiMax, Automotive Grade

**Dimensions**

D	3.81mm MAX
L	6.1mm MAX
LL	25.4mm MIN
F	0.51mm +0.025/-0.076mm

Packaging Specifications

Packaging:	Bulk, Bag
Packaging Quantity:	200

General Information

Supplier:	KEMET
Series:	AxiMax 400 Auto X8L HT150C
Description:	AxiMax, Automotive Grade
Features:	Automotive Grade
RoHS:	Yes
Termination:	Tin
Failure Rate:	N/A
Qualifications:	AEC-Q200
AEC-Q200:	Yes
Halogen Free:	Yes

Specifications

Capacitance:	2.2 uF
Capacitance Tolerance:	10%
Voltage DC:	25 VDC
Dielectric Withstanding Voltage:	62.5 VDC
Temperature Range:	-55/+150C
Temperature Coefficient:	X8L
Dissipation Factor:	2.50% 25C
Aging Rate:	3% Loss/Decade Hour
Insulation Resistance:	450 MOhms