
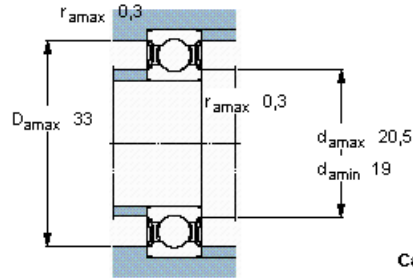


Deep groove ball bearings, single row, seal on both sides

Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
17	35	10	6,37	3,25	0,137	-	13000	0,039	6003-2RSH *

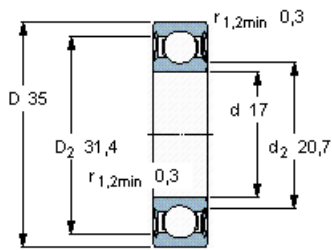

Calculation factors

$k_r = 0,025$
 $f_0 = 14$