
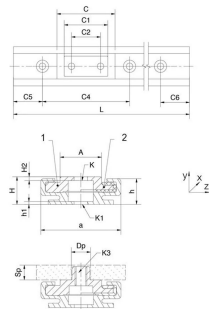


drylin® N guide carriage | installation size 27 |
iglidur® J sliding element
NW-02-27

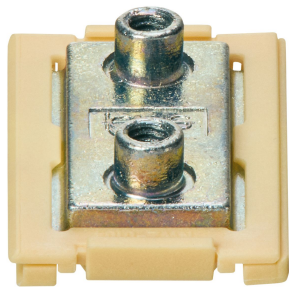

drylin® N guide carriage | installation size 27 |
iglidur® J sliding element

- Material sliding element: iglide® J
- Mounting type: Threaded bosses
- Installation size: 27
- Load capacity, stat.: 500 N

Product description

Introducing the drylin N guide carriage installation size 27 featuring the iglidur J sliding element. This innovative product combines durability and efficiency, designed for seamless movement with a robust load capacity of 112 lbs. The threaded bosses ensure easy mounting, making it a practical choice for various applications. Upgrade your systems with this reliable guide carriage that promises smooth operation and longevity. Perfect for those seeking quality and performance in one package.

Manufacturing and installation tolerances

H-tolerance	±0,35 mm
-------------	----------

Mechanical properties

Static load capacity	500 N
----------------------	-------

Dimensions

A	14 mm
C	40 mm
C1	30 mm
C2	20 mm
Sp	5 mm
Dp	6.5 mm
Thread K3	M4



General properties

Sliding element material	iglidur® J
Floating bearing	none
Type of fastening	Threaded pin
High temperature	No

Certificates and standards

