

# Snipe Nose Pliers



## DESCRIPTION:

Snipe nose pliers for professionals with bent, smooth and short jaws

Special pliers made from high grade special steel for extremely high requirements

For gripping, bending and holding

Box joint - double leaf spring

Precise jaw adjustment without backlash

High gloss steel polished surface


Ergonomically formed bicoloured hand guard - dissipative anti-slide material

The pliers have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas

## SPECIFICATION:

Length	130 mm
A - Head width	10 mm
B - Head length	20 mm
C - Head thickness	6.5 mm
D - Jaws thickness	2 mm
E - Jaws width	1 mm
F - Jaws length	10 mm
Weight	62 g

Art. Nr.  
RND 550-00265

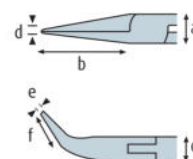

a=10mm/.394"  
b=20mm/.788"  
c=6.5mm/.250"  
d=2mm/.079"  
e=1mm/.039"  
f=10mm/.394"