

## FEATURES

- Non-toxic
- Moulded in index card slot on the front of the storage bin for product identification
- Accept dividers to further organise contents
- Open front for ease of access to contents
- Ergonomic and durable design

## RS PRO PP Storage Bin Storage Bin, 246mm x 335mm, Blue

RS Stock No.: 390-3659



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

## Product Description

From RS Pro range of high-quality plastic storage bins made from robust polypropylene designed for simple and effective small parts organisation and storage in the workplace and in the home. These storage bins are stackable and can be stacked on top of one another to provide both a space saving solution to your storage needs and ease of handling.

[390-3299](#) is a 103 x 100 x 50mm Red Stack & Nest Bin [390-3328](#) is a 103 x 100 x 50mm Blue Stack & Nest Bin

[390-3356](#) is a 172 x 109 x 80mm Red Stack & Nest Bin

[390-3384](#) is a 172 x 109 x 80mm Blue Stack & Nest Bin

[390-3407](#) is a 250 x 179 x 130mm Red Stack & Nest Bin

[390-3435](#) is a 250 x 179 x 130mm Blue Stack & Nest Bin

[390-3457](#) is a 349 x 239 x 130mm Red Stack & Nest Bin

[390-3491](#) is a 349 x 239 x 130mm Blue Stack & Nest Bin

[390-3558](#) is a 349 x 239 x 180mm Blue Stack & Nest Bin

[390-3514](#) is a 349 x 239 x 180mm Red Stack & Nest Bin

[390-3570](#) is a 470 x 385.5 x 180mm Red Stack & Nest Bin

[390-3609](#) is a 470 x 385.5 x 180mm Blue Stack & Nest Bin

[390-3659](#) is a 510 x 335 x 246mm Blue Stack & Nest Bin

[390-3621](#) is a 510 x 335 x 246mm Red Stack & Nest Bin

## General Specifications

<b>Material</b>	PP
<b>Colour</b>	Blue
<b>Size</b>	Size 7
<b>Application</b>	Home, Office ,Warehouse ,Laboratory, Hospital, Garage

## Mechanical Specifications


<b>Volume</b>	27.11 litres
<b>Maximum Container Stack Height</b>	4mm
<b>Maximum Stack Load Capacity</b>	75kg
<b>Weight</b>	28kg

External dimensions		
<b>Dimension</b>	510mm x 335mm x 246mm	
<b>Depth</b>	510mm	(Overall)
<b>Width</b>	335mm	(Overall)
<b>Height</b>	246mm	(Overall)
<b>Base Length</b>	410mm	(Overall)

Internal dimensions	
Dimension	449mm x 214mm x 244mm
Depth	449mm
Width	214mm
Height	244mm
Base Length	370mm

### Operation Environment Specifications

Operating Temperature Range	-15°C to 50°C
-----------------------------	---------------

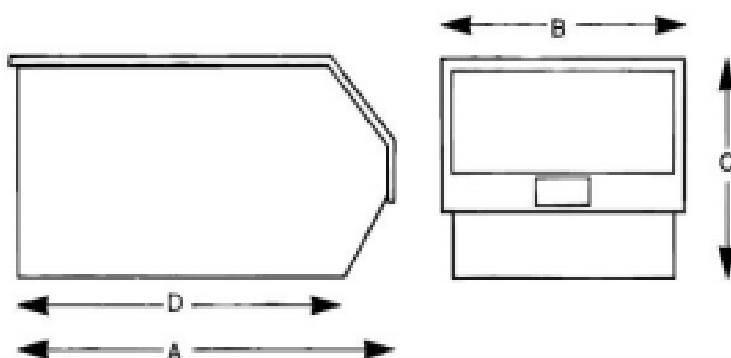

All Dimensions in mm	SIZE 1	SIZE 2	SIZE 3	SIZE 4	SIZE 5	SIZE 6	SIZE 7
(A) Overall Length	103	172	250	349	349	385.5	510
(B) Overall Width	100	109	179	239	239	470	335
(C) Overall Height	50	80	130	130	180	180	246
(D) Overall Base Length	83	135	205	313	303	316	410
(A) Internal Length	95	160	234	332	332	326	449
(B) Internal Width	76	74	116	154	154	362	214
(C) Internal Height	47	77	128	128	174	173	244
(D) Internal Base Length	80	135	195	300	295	275	370
Volume (Litres)	0.37	0.9	3.87	7.49	9.74	21.01	27.11
Maximum Container Stack Height (See Details Opposite)	7	5	4	4	4	5	4
Maximum Stack Load Capacity (Kgs)	8	8	25	40	60	80	75
Dividers (Front to Back)	-	-	-	400-9073	400-9095	400-8373	400-9089
Dividers (Left to Right)	-	-	400-8339	400-8367	400-8351	-	400-8345