


Part Number: 1954XX54

Type	Size	Rating	Description
LED	M22	See table	Standard Bezel Tri-Colour Panel Indicator

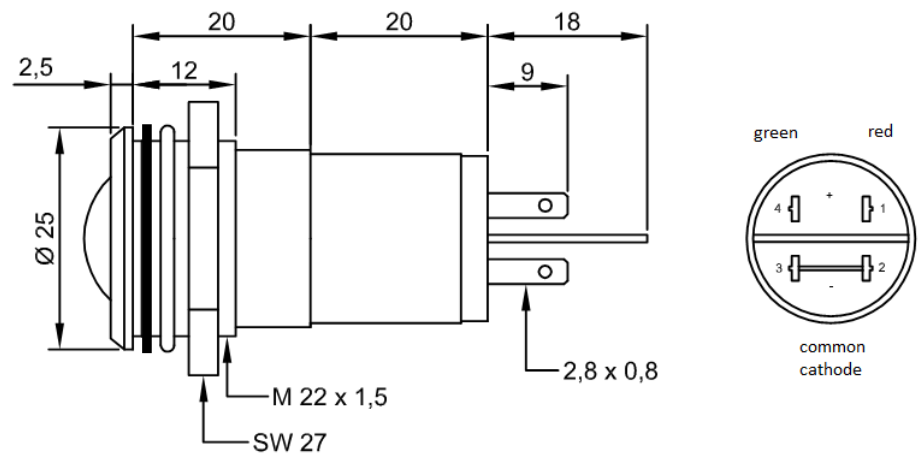

Part #	Colour	Voltage	Current (nom mA)	Intensity (mcd)
1954X354	Red/Green/Yellow	24Vdc	2 / 8 / 10	250 / 250 / 500
1954X454	Red/Green/Yellow	28Vdc	1 / 4 / 5	125 / 125 / 250
1954X554	Red/Green/Yellow	36Vdc	1 / 5 / 6	125 / 135 / 260
1954X654	Red/Green/Yellow	48Vdc	1 / 4 / 5	125 / 125 / 250
1954X754	Red/Green/Yellow	60Vdc	1 / 1 / 2	100 / 100 / 200

Notes:

- 1 X = Chrome Bezel finish. 0 = Satin, 1 = Black, 2 = Matt
- 2 Electrical & optical data are measured at an ambient temperature of 25°C
- 3 Storage temperature -25 °C to +80°C
- 4 Application temperature -20 °C to +60°C
- 5 Voltage tolerance ±10%
- 6 Due to component tolerances, colour temperature variations may be observed
- 7 The terminals are not qualified for soldering
- 8 Degree of protection IP67 when used with the supplied gasket
- 9 The plastic(polycarbonate) has limited chemical resistance
- 10 RoHS & REACH SVHC compliant