


Technical data sheet

Article number:
150-11294

ASI-Clip

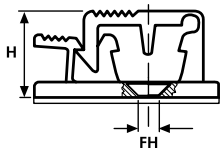

Product Family	ASI-Clip
Material	Polyamide 6.6, high impact modified (PA66HIR)
Colour	Natural (NA)
Fixation Method	Pasting / Stick
Flammability	UL 94 HB (excluding adhesive)
for Hole Ø (FH)	3.3 mm
Height (H)	11.7 mm
Length (L)	25.0 mm
Operating Temperature	-40 °C to +80 °C
Package Content packed in	pcs.
Pack Cont.	500 pcs.
ROHS compliant	Yes
Variant	Closed
Width (W)	20.0 mm

RoHS 