

HC-B 16-TMSO1STM32G/M32S-EEE - Housing



1580492

<https://www.phoenixcontact.com/in/products/1580492>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



HEAVYCON ADVANCE sleeve housing B16, with high-grade steel screw locking (hexagonal socket-head), salt water resistant aluminum, height 100 mm, with thread, 1xM32 straight and M32 lateral cable outlet, without surface; conductive seal (EMC properties)

Commercial data

Item number	1580492
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BF7
Product key	AF7AAA
GTIN	4046356438223
Weight per piece (including packing)	364.45 g
Weight per piece (excluding packing)	364 g
Customs tariff number	85389099
Country of origin	DE

HC-B 16-TMSO1STM32G/M32S-EEE - Housing



1580492

<https://www.phoenixcontact.com/in/products/1580492>

Technical data

Notes

General	For contact inserts HC-B16, BB32, D40, DD72, HS6, HV6, M, K
---------	---


Product properties

Product type	Housing with screw locking
Housing type	Sleeve housing
Application	Offshore/EMC
Type	B16
Type of the screw connection	1x M32 / 1x M32
Fixing screws	M6 (screw head: 5 mm Allen screw)
Cable outlet	straight

Connection data

Tightening torque	3 Nm (Locking screw)
-------------------	----------------------

Dimensions

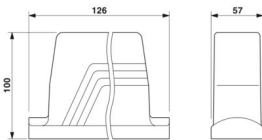Dimensional drawing	
Width	57 mm
Height	100 mm
Length	126 mm

Installation dimensions

Width of the assembly cutout	35 mm
Length of the assembly cutout	86 mm

Material specifications

Seal material	NBR, conductive
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	uncoated
Locking latch material	Stainless steel

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
	IP68 (0.2 bar/24 h)
	IP69
Enclosure rating (NEMA)	4 (NEMA 250)
	4X (NEMA 250)

HC-B 16-TMSO1STM32G/M32S-EEE - Housing



1580492

<https://www.phoenixcontact.com/in/products/1580492>

	6P (NEMA 250)
	12 (NEMA 250)
Ambient temperature (operation)	-40 °C ... 125 °C

Mechanical properties

Mechanical data


Type of the screw connection	1x M32 / 1x M32
------------------------------	-----------------

Mounting

Assembly note	In order to guarantee that the protective conductor contact functions even when plugged in at an angle, the two panel-mount flanges must have sufficient electrical contact with the metal mounting panel.
	To ensure optimum shielding, any insulating power coating must be removed from the profile gasket area on the control cabinet panel. Tightening torque of locking screw: 3 Nm.
Fixing screws	M6 (screw head: 5 mm Allen screw)


Drawings

Dimensional drawing

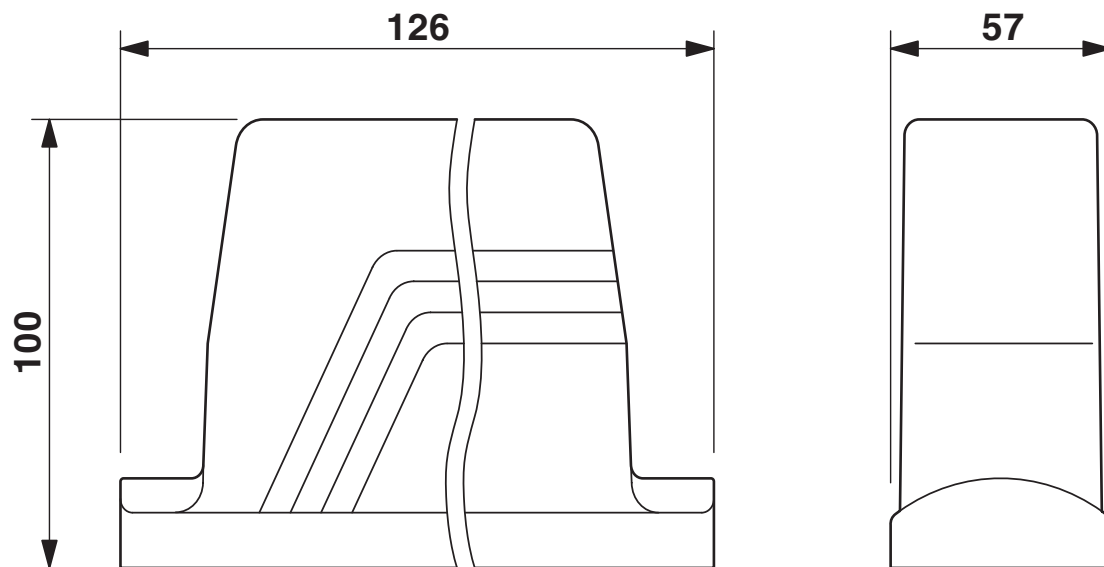

Dimensional drawing

Dimensional drawing

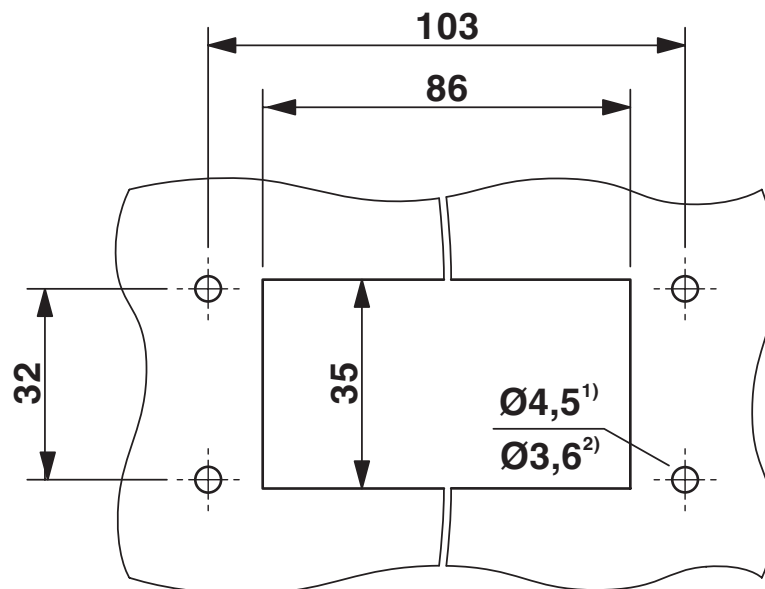

Mounting cutout

1) when M4 screws are used

2) when self-tapping Torx® screws are used (Torx® 20, M4)

HC-B 16-TMSO1STM32G/M32S-EEE - Housing



1580492

<https://www.phoenixcontact.com/in/products/1580492>

Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1580492>



EAC

Approval ID: RU C-DE.AI30.B.01102

HC-B 16-TMSO1STM32G/M32S-EEE - Housing



1580492

<https://www.phoenixcontact.com/in/products/1580492>

Classifications

ECLASS

ECLASS-11.0	27440202
ECLASS-12.0	27440202
ECLASS-13.0	27440202

ETIM

ETIM 9.0	EC000437
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

1580492

<https://www.phoenixcontact.com/in/products/1580492>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

HC-B 16-TMSO1STM32G/M32S-EEE - Housing



1580492

<https://www.phoenixcontact.com/in/products/1580492>

Accessories

HC-B-AF - Panel-mount flange

1686533

<https://www.phoenixcontact.com/in/products/1686533>

Panel-mount flange for HEAVYCON ADVANCE housing




HC-B-AF-SET - Panel-mount flange

1604638

<https://www.phoenixcontact.com/in/products/1604638>

Panel-mount flange for HEAVYCON ADVANCE housing, set consisting of:
2 panel-mount flanges with 4 self-tapping screws (M4, Torx®) and 4 fan-type washers

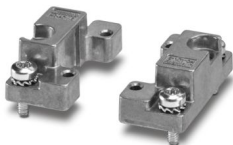

HC-B 16-TMSO1STM32G/M32S-EEE - Housing



1580492

<https://www.phoenixcontact.com/in/products/1580492>

HC-B 16-TMS-SD-IP50 - Protective cover

1690752

<https://www.phoenixcontact.com/in/products/1690752>



Protective cover B16, with clip locking, protective cover material: PA, height: 31.2 mm, seal: no, with lanyard

HC-B 16-TMS-SD-IP66 - Protective cover

1411517

<https://www.phoenixcontact.com/in/products/1411517>



HEAVYCON ADVANCE, IP66, B16 protective cover, for panel mounting side, with screw locking, with retaining cord, diameter of retaining cord eyelet: 3 mm

HC-B 16-TMSO1STM32G/M32S-EEE - Housing



1580492

<https://www.phoenixcontact.com/in/products/1580492>

G-INS-M32-M68N-PNES-GY - Cable gland

1411127

<https://www.phoenixcontact.com/in/products/1411127>



Cable gland, material for screw connection: PA, application: Standard, external cable diameter 15 mm ... 21 mm, shielding: no, connecting thread: M32 x 1.5, color: silver-gray RAL 7001

G-INS-M32-M68N-PNES-BK - Cable gland

1411136

<https://www.phoenixcontact.com/in/products/1411136>



Cable gland, material for screw connection: PA, application: Standard, external cable diameter 15 mm ... 21 mm, shielding: no, connecting thread: M32 x 1.5, color: jet black RAL 9005

HC-B 16-TMSO1STM32G/M32S-EEE - Housing

1580492

<https://www.phoenixcontact.com/in/products/1580492>



G-INS-M32-M68N-NNES-S - Cable gland

1411166

<https://www.phoenixcontact.com/in/products/1411166>



Cable gland, material for screw connection: Brass, nickel-plated, application: Standard, external cable diameter 15 mm ... 21 mm, shielding: no, connecting thread: M32 x 1.5, color: silver, with O-ring

HC-M-KV-M32(19-27) - Cable gland

1646010

<https://www.phoenixcontact.com/in/products/1646010>



Metal screw connection up to 5 bar, thread length: 8 mm, cable diameter: 19 - 27 mm, WAF 43, screw connection: M32

HC-B 16-TMSO1STM32G/M32S-EEE - Housing



1580492

<https://www.phoenixcontact.com/in/products/1580492>

G-INSEC-M32-M68N-NCRS-S - Cable gland

1411191

<https://www.phoenixcontact.com/in/products/1411191>



Cable gland, material for screw connection: Brass, nickel-plated, application: EMC, external cable diameter 14 mm ... 21 mm, shielding: yes, connecting thread: M32 x 1.5, color: silver, with O-ring

HC-M-KV-Z-M32 - Cable gland

1646162

<https://www.phoenixcontact.com/in/products/1646162>



Metal screw connection with strain relief clamp, thread length: 8 mm, cable sealing area: 18 - 27 mm, clamping area: 19 - 30 mm, SW 40, screw connection: M32

HC-B 16-TMSO1STM32G/M32S-EEE - Housing

1580492

<https://www.phoenixcontact.com/in/products/1580492>



HC-M-KV-T-M32 - Cable gland

1646201

<https://www.phoenixcontact.com/in/products/1646201>

Metal screw connection with cable bend protection and strain relief, thread length: 8 mm, cable sealing area: 18 - 27 mm, clamping area: 20 - 30 mm, SW 40, screw connection: M32



REDUC-M-KV-M32/M25 - Reducing adapter

1647637

<https://www.phoenixcontact.com/in/products/1647637>

Reducing adapter, connecting thread: M32 x 1.5, color: silver, with O-ring



HC-B 16-TMSO1STM32G/M32S-EEE - Housing



1580492

<https://www.phoenixcontact.com/in/products/1580492>

ENLAR-M-KV-M32/M40 - Extension adapter

1647682

<https://www.phoenixcontact.com/in/products/1647682>

Extension adapter, connecting thread: M32 x 1.5, color: silver, with O-ring



HC-M-BS-M32 - Screw plug

1645862

<https://www.phoenixcontact.com/in/products/1645862>

Screw plug, material for screw connection: Brass, nickel-plated, connecting thread: M32 x 1.5, color: silver



HC-B 16-TMSO1STM32G/M32S-EEE - Housing

1580492

<https://www.phoenixcontact.com/in/products/1580492>



HC-B 16-TMS-EEE-PR-DI - Profile gasket

1409817

<https://www.phoenixcontact.com/in/products/1409817>

Profile gasket for sleeve housing type B16.....EEE



SF-BIT-HEXB 5-89 - Screw insert

1208911

<https://www.phoenixcontact.com/in/products/1208911>

Screw bit, hexagonal with ball head, E6.3-1/4" drive, size: Hex 5 x 89 mm, hardened, suitable for holder according to DIN 3126-F 6.3/ISO 1173



HC-B 16-TMSO1STM32G/M32S-EEE - Housing

1580492

<https://www.phoenixcontact.com/in/products/1580492>



SF-M BH - Screwdriver

1212070

<https://www.phoenixcontact.com/in/products/1212070>



Bit screwdriver, with 1/4" quick-action chuck, handle length 119 mm, 2-component handle, with non-slip grip, suitable for bits according to DIN 3126-C 6.3 and E 6.3/ISO 1173, magnetic

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in