




Process adapter clamp ISO 2852

ADAPT ISO2852 DN80

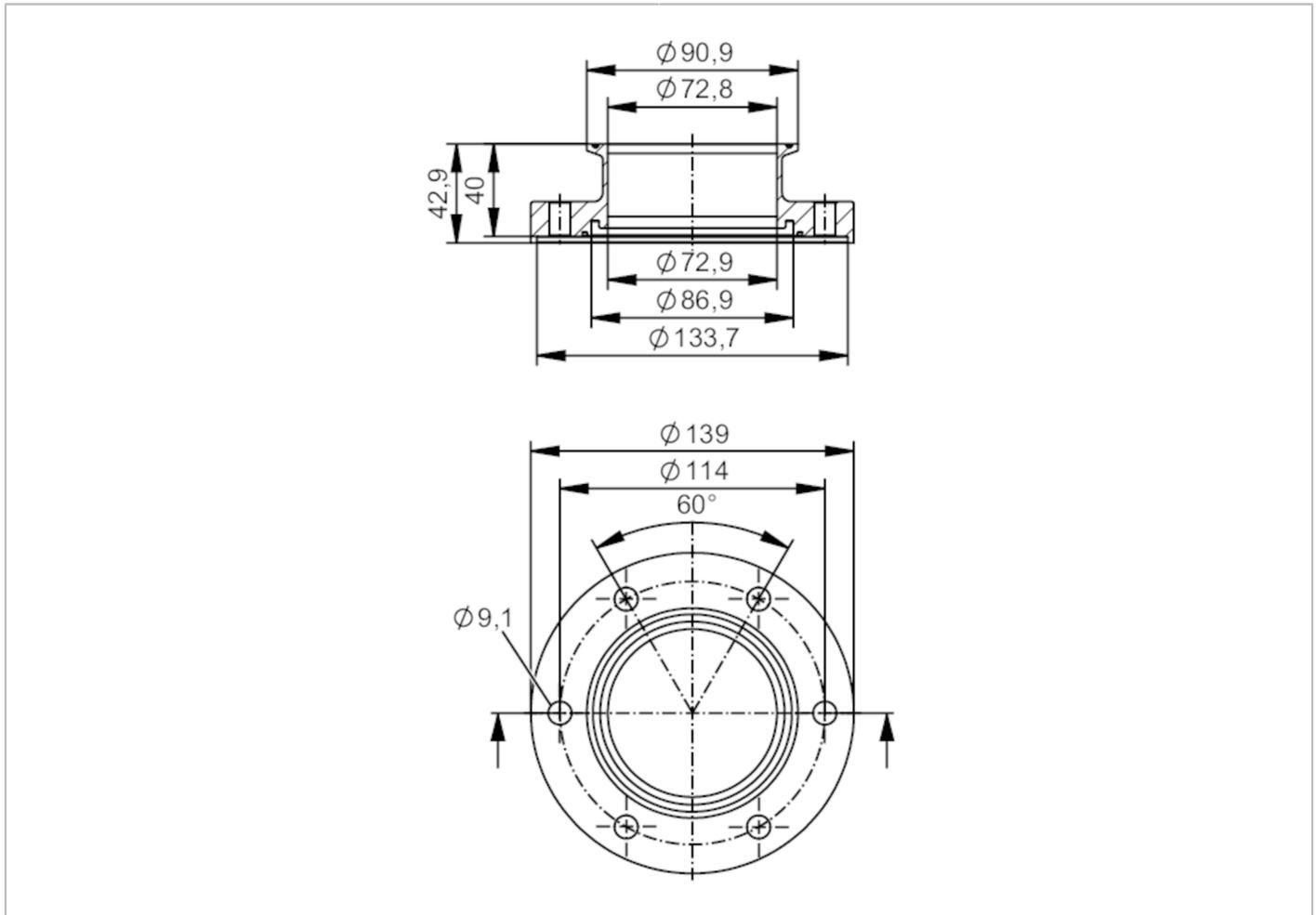

Application	
Design	for volumetric flow meters SMF
Application	food and beverage industry; hygienic systems
Pressure rating	16 bar 1.6 MPa
Tests / approvals	
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.
Mechanical data	
Weight [g]	3935
Materials	stainless steel (316L/1.4404)
Nominal diameter	DN80 (3")
Sensor connection	ifm-specific device flange
Process connection	Clamp ISO 2852
Process connection suitable for pipe standard	(ISO 2037); (DIN EN 10357 Series D)
Surface characteristics Ra/Rz of the wetted parts	Ra \leq 0.4 μ m

E40485



Process adapter clamp ISO 2852

ADAPT ISO2852 DN80

Accessories	
Items supplied	screws 12
Remarks	
Pack quantity	2 pcs.