

Identification ties and plates for marking cable bundles


Arrowtag

The plates are suitable for applying to larger pipes and cables before or after termination has taken place.

They can be marked with Ovalgrip markers or manually using the T82 series of indelible markers pens.

Features and Benefits

- Blank nylon arrowhead shape plate fixed with a cable tie
- Identify with a T82 pen or Ovalgrip markers
- AT1 for 7 size 50 Ovalgrip markers
- AT2 for 8 size 85 Ovalgrip markers
- AT3 for 14 size 85 Ovalgrip markers
- Custom printed plaques are available on request

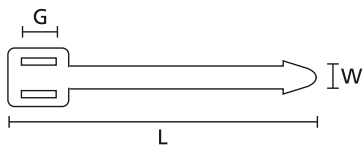


AT1



AT2



AT3

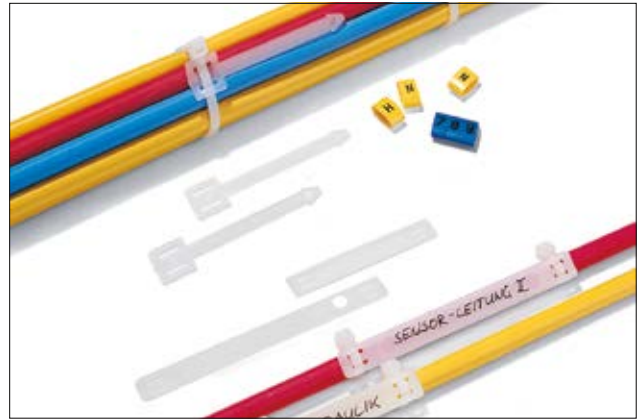

A clearly better way of identifying cables and pipes.

MATERIAL	Polyamide 6.6 (PA66)
Operating Temperature	-40 °C to +85 °C, (+105 °C, 500 h)
Flammability	UL94 V2



TYPE	Length (L)	Width (W)	Strap Width max. (G)	Pack Cont.	Colour	Article-No.
AT1	62.5	4.7	7.4	100 pcs.	Black (BK)	151-41110
	62.5	4.7	7.4	100 pcs.	Natural (NA)	151-41119
AT2	63.0	9.0	6.4	100 pcs.	Black (BK)	151-41210
	63.0	9.0	6.4	100 pcs.	Natural (NA)	151-41219
AT3	100.0	9.0	6.4	100 pcs.	Black (BK)	151-41310
	100.0	9.0	6.4	100 pcs.	Natural (NA)	151-41319

All dimensions in mm. Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.

TYPE	Description	Colour	Pack Cont.	Article-No.
T82S-BK	Indelible Marker Pen	Black (BK)	2 pcs.	500-50820
T82R-RD	Indelible Marker Pen	Red (RD)	2 pcs.	500-50822

Subject to technical changes.

Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.