




Heads for spring return pushbuttons - unmarked				
Shape of head	Type of push	Colour	Reference	Weight kg
For the metal range				
	Flush	Multi-colour (1)	9001 KR1U	0.087
	Projecting	Multi-colour (1)	9001 KR3U	0.090
	Recessed (high guard)	Multi-colour (1)	9001 KR2U	0.087
For the plastic range				
	Flush	Multi-colour (1)	9001 SKR1U	0.050
	Projecting	Multi-colour (1)	9001 SKR3U	0.050
	Recessed (high guard)	Multi-colour (1)	9001 SKR2U	0.050

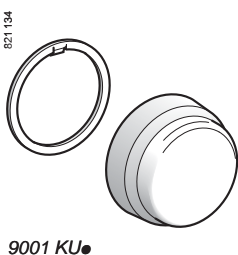

Accessories for heads 9001 KR●U				
Description	Application	Colour	Reference	Weight kg
Rubber boots	Pushbuttons	Black	9001 KU1	0.027
		Green	9001 KU5	0.027
		Red	9001 KU2	0.027
		Clear	9001 KU7	0.027
Rod for spring return wobblestick	Pushbuttons	Chromium plated	9001 K8	0.120

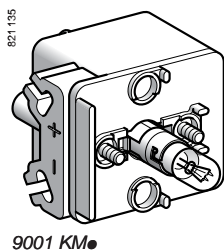

Light blocks for pilot lights and illuminated pushbuttons						
Supply	Light source	Type	Supply voltage V	Colour	Reference	Weight kg
Direct supply via integral resistance	BA 9s bulb (included)	Incandescent	≈ 12	–	9001 KM32	0.050
			≈ 24	–	9001 KM35	0.050
			≈ 120	–	9001 KM38	0.050
			≈ 230	–	9001 KM25	0.050
Direct supply via integral transformer	BA 9s 6 V bulb (included)	Incandescent	~ 120	–	9001 KM1	0.144
			~ 230	–	9001 KM7	0.144
			≈ 380 - 480	–	9001 KM5	0.144
Shallow depth	24 V bulb	Incandescent	≈ 24 - 28	–	9001 KM55	0.115
			LED	≈ 24 - 28	Red	9001 KM55LR
		Green	9001 KM55LG	0.115		
		Yellow	9001 KM55LY	0.115		
	120 V bulb	Incandescent	≈ 110 - 120	–	9001 KM58	0.115
			LED	≈ 110 - 120	Red	9001 KM58LR
		Green	9001 KM58LG	0.115		
		Yellow	9001 KM58LY	0.115		

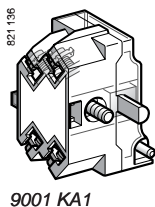

Contact blocks with protected terminals						
Description		Type of contact			Reference	Weight kg
Standard contact blocks	–	–	–	1	9001 KA1 (2)	0.027
	–	1	–	–	9001 KA2 (2)	0.023
	–	–	1	–	9001 KA3 (2)	0.023
Late break contact blocks	–	–	–	1	9001 KA4	0.027
	–	–	1	–	9001 KA5	0.023
Early break contact blocks	–	1	–	–	9001 KA6	0.023
Logic reed contact blocks	Hermetically sealed	1	–	–	9001 KA41 (2)	0.045
		–	1	–	9001 KA42 (2)	0.045
		–	–	1	9001 KA43 (2)	0.045
Power reed contact blocks	Hermetically sealed	1	–	1	9001 KA51 (2)	0.045
		–	1	–	9001 KA52 (2)	0.045
		–	–	1	9001 KA53 (2)	0.045

(1) Includes set of 7 different coloured caps for customer installation: black, green, red, yellow, blue, white and orange.

(2) It is possible to mount up to 3 levels of contact blocks (maximum of 6 contacts blocks) on 9001 K and 9001 SK references (see page 36053-EN_Ver6.0/3).

Aluminium legend plates for metal range

Unmarked

Description	Background colour	Reference	Weight kg
Size 1 (40 x 43 mm)	Black	9001 KN200	0.005
	Red	9001 KN200R	0.005
Size 2 (44 x 50 mm)	Black	9001 KN300	0.005
	Red	9001 KN300R	0.005

Marked

Description	Legend plate colour	Marking	Reference	Weight kg
English text (40 x 43 mm)	Black or red background	START	9001 KN201	0.005
		STOP (red background)	9001 KN202	0.005
		ON	9001 KN203	0.005
		OFF (red background)	9001 KN204	0.005
		EMERGENCY STOP (red background)	9001 KN205	0.005
		FORWARD	9001 KN206	0.005
		REVERSE	9001 KN207	0.005
		CLOSE	9001 KN208	0.005
		OPEN	9001 KN209	0.005
		DOWN	9001 KN210	0.005
		UP	9001 KN211	0.005
		SLOW	9001 KN213	0.005
		HIGH	9001 KN214	0.005
		LOW	9001 KN215	0.005
		RESET	9001 KN233	0.005
		OFF-ON	9001 KN245	0.005
		OPEN-CLOSE	9001 KN246	0.005
		HAND-OFF-AUTO	9001 KN260	0.005
		PULL TO START/PUSH TO STOP	9001 KN279	0.005
		English text (44 x 50 mm)	Black	PULL TO START/PUSH TO STOP
French text (40 x 43 mm)	Black or red background	MARCHE	9001 KN201F	0.005
		ARRÊT (red background)	9001 KN202F	0.005
		AVANT	9001 KN206F	0.005
		ARRIERE	9001 KN207F	0.005
		FERME	9001 KN208F	0.005
		OUVERT	9001 KN209F	0.005
		BAS	9001 KN210F	0.005
		HAUT	9001 KN211F	0.005
		VITE	9001 KN214F	0.005
		LENT	9001 KN215F	0.005
		REARMEMENT	9001 KN223F	0.005



Plastic legend plates for plastic range

Unmarked


Description	Background colour	Reference	Weight kg
Size 1 (57 x 57 mm)	White	9001 KN100WP	0.005
	Black	9001 KN100BP	0.005

Marked


Description	Legend plate colour	Marking	Reference	Weight kg
English text (57 x 57 mm)	White	START	9001 KN101WP	0.005
		STOP	9001 KN102WP	0.005
		ON	9001 KN103WP	0.005
		OFF	9001 KN104WP	0.005
		EMERGENCY STOP	9001 KN105WP	0.005
		FORWARD	9001 KN106WP	0.005
		REVERSE	9001 KN107WP	0.005
		CLOSE	9001 KN108WP	0.005

Plastic legend plates for plastic range (continued)

Marked						
Description	Legend plate colour	Marking	Reference	Weight kg		
English text (57 x 57 mm)	White background	OPEN	9001 KN109WP	0.005		
		DOWN	9001 KN110WP	0.005		
		UP	9001 KN111WP	0.005		
		SLOW	9001 KN113WP	0.005		
		HIGH	9001 KN114WP	0.005		
		LOW	9001 KN115WP	0.005		
		RESET	9001 KN133WP	0.005		
		OPEN-CLOSE	9001 KN146WP	0.005		
		OFF-ON	9001 KN145WP	0.005		
		HAND-OFF-AUTO	9001 KN160WP	0.005		
		PULL TO START/PUSH TO STOP	9001 KN179WP	0.005		
		French text (57 x 57 mm)	White background	MARCHE	9001 KN101WPF	0.005
				ARRET (red background)	9001 KN102WPF	0.005
				AVANT	9001 KN106WPF	0.005
ARRIERE	9001 KN107WPF			0.005		
FERME	9001 KN108WPF			0.005		
OUVERT	9001 KN109WPF			0.005		
BAS	9001 KN110WPF			0.005		
HAUT	9001 KN111WPF			0.005		
VITE	9001 KN114WPF			0.005		
LENT	9001 KN115WPF			0.005		
TIRER POUR MARCHE / POUSSER POUR ARRET	9001 KN179WPF			0.005		

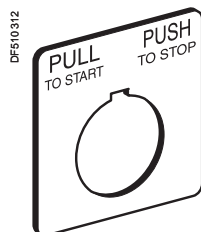

9001 KN179WP

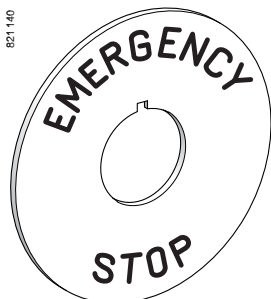

9001 KN8330



9001 G22




9001 ●31

Emergency stop legend plate (plastic)


Description	Legend plate colour	Marking	Reference	Weight kg
Ø 76	Yellow	EMERGENCY STOP	9001 KN7330	0,005
Ø 90	Yellow	EMERGENCY STOP	9001 KN8330	0,005

Caps and knobs


Description	Application	Color	Reference	Weight kg
Ø 41 mushroom knob with set screw	For non-illuminated pushbutton	Red	9001 K94R	0.005
Ø 57 mushroom knob with set screw	For non-illuminated pushbutton	Red	9001 K93R	0.005
Ø 41 mushroom knob	For illuminated pushbutton	Red	9001 R22	0.005
Ø 57 mushroom knob	For illuminated pushbutton	Red	9001 R21	0.005
Ø 41 lens caps	Mushroom head illuminated pushbutton	Yellow	9001 Y22	0.005
		Green	9001 G22	0.005
Standard lens	For pilot light	Red	9001 R9	0.005
		Green	9001 G9	0.005
		Blue	9001 L9	0.005
		Yellow	9001 Y9	0.005
		White	9001 W9	0.005
		Clear	9001 C9	0.005
Lens caps "Fresnel lens"	For pilot light	Red	9001 R31	0.005
		Green	9001 G31	0.005
		Blue	9001 L31	0.005
		Yellow	9001 Y31	0.005
		White	9001 W31	0.005
		Clear	9001 C31	0.005
Standard knob	For selector switch	Black	9001 B11	0.005
		Red	9001 R8	0.005
		Green	9001 G8	0.005
		Blue	9001 L8	0.005
		Yellow	9001 Y8	0.005
		White	9001 W8	0.005
Long knob	For selector switch	Black	9001 B25	0.005
		Red	9001 R24	0.005
		Green	9001 G24	0.005
		Blue	9001 L24	0.005
		Yellow	9001 Y24	0.005
		White	9001 W24	0.005

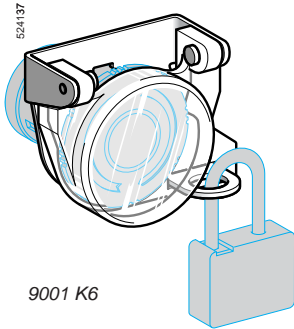


9001 K6

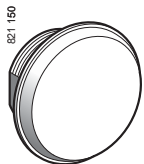


9001 K52

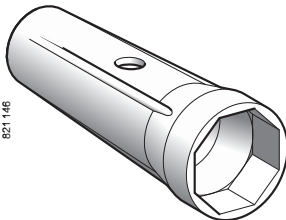


9001 K95

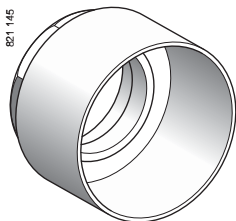

9001 K48

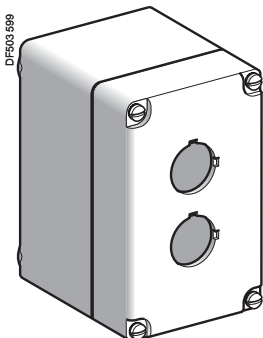

9001 KY2

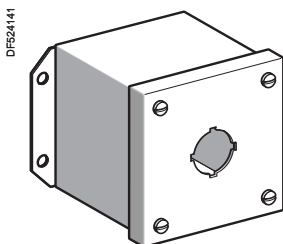

9001 KYSS1

Other accessories

Description	Application	Colour	Reference	Weight kg	
Super bright LED bulbs	24 V / 9001 ●●●35L (1) or 48 V / 9001 ●●●36L (1) or 120 V / 9001 ●●●38L (1)	Red (1)	6508805210	0.010	
		Green (1)	6508805212	0.010	
		Amber (1)	6508805211	0.010	
		Blue (1)	6508805213	0.010	
		White (1)	6508805214	0.010	
LED bulbs	120 V / 9001 ●●●1L (1) or 230 V / 9001 ●●●7L (1) or 380 V / 9001 ●●●5L (1)	Red (1)	6508805201	0,010	
		Yellow (1)	6508805202	0,010	
		Green (1)	6508805203	0,010	
Incandescent bulbs	Resistor light blocks	~ 12 V - code "32" (2)	–	2550101037	0.002
		~ 24 V - code "35" (2)	–	2550101002	0.002
		~ 48 V - code "36" (2)	–	2550101025	0.002
		~ 120 V - code "38" (2)	–	2550101027	0.002
		~ 240 V - code "25" (2)	–	2550101027	0.002
	Transformer light blocks	~ 120 V 50/60 Hz - code "1" (2)	–	2550101020	0.002
		~ 230 V 50/60 Hz - code "7" (2)	–	2550101020	0.002
		~ 380 V 50/60 Hz - code "5" (2)	–	2550101020	0.002
		~ 600 V 50/60 Hz - code "6" (2)	–	2550101020	0.002
Closing plates	–	Grey	9001 K51	0.020	
	–	Metal	9001 K52	0.028	
Screwdriver (3)	–	–	9001 K69	0.150	
Tightening wrench	Fixing nut	–	9001 K95	0.064	
	Boot	–	9001 K1	0.150	
Guards:	Mushroom head pushbutton	Ø 35 mm	–	9001 K48	0.028
		Ø 41 mm	–	9001 K56YM	0.036
		Ø 60 mm	–	9001 K685	0.030
Set of 7 different coloured caps	Pushbutton	Black, green, red, yellow, blue, white, orange	9001 T8U	0.005	
Bulb extractor	–	–	XBF X13	0.005	
Padlock attachment	For selector switch	–	9001 K7	0.150	
	For pushbutton	–	9001 K6	0.150	
	For Emergency stop	–	9001 K62	0.150	
Alternate action module	Push on - Push off module (4)	–	9001 K85	0.025	

Enclosures

Type	Conduit threads	NEMA ratings	N° of 30 mm holes	Reference	Weight kg
Aluminium	3/4"	1, 3, 4, 6, 12, 13	1	9001 KY1	1.170
			2	9001 KY2	1.279
			3	9001 KY3	1.597
			4	9001 KY4	1.846
	14 mm	1, 3, 4, 6, 12, 13	1	9001 TY1	1.170
			2	9001 TY2	1.279
			3	9001 TY3	1.597
			4	9001 TY4	1.846
Stainless steel	3/4" Knockout	1, 3, 4, 4X, 13	1	9001 KYSS1	1.061
			2	9001 KYSS2	1.370
			3	9001 KYSS3	1.715
			4	9001 KYSS4	1.855
Plastic	3/4" Knockout	1, 3, 4, 4X, 13	1	9001 SKY1	0.690
			2	9001 SKY2	0.690
			3	9001 SKY3	0.790

(1) LED light modules require the color cap color and the LED be the same or use a clear color cap.

(2) Voltage Assembly Codes.

(3) Screwdriver with special tip for mounting contact blocks.

(4) N/O circuits require KA4 or KA6 contact blocks.