




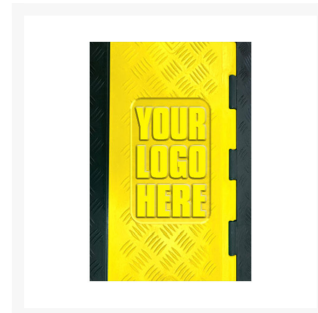

5-Channel Low-Profile Guard Dog® ADA Cable Protector for .75" Cables - GD5X75

Product Images

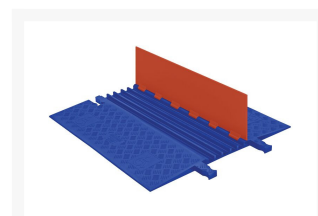

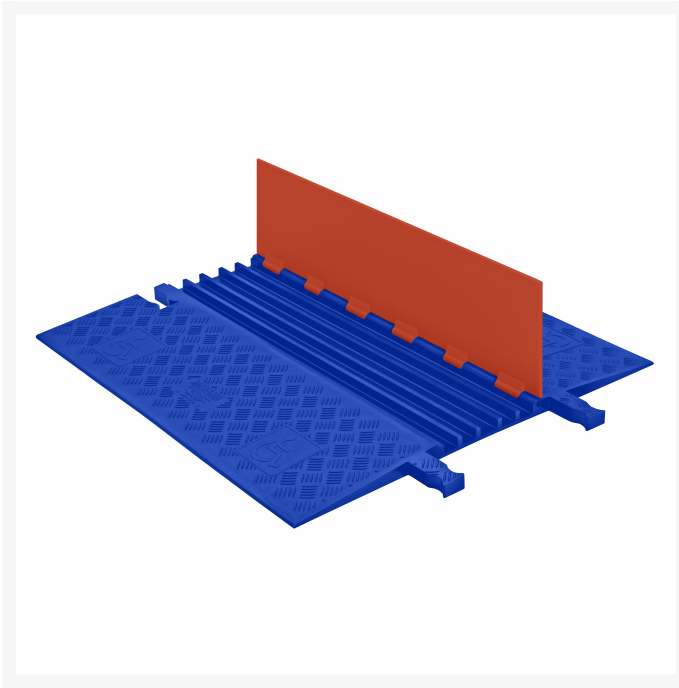

Short Description

- Protects cables and hoses up to .75" outside dia.
- Dog Bone® connectors to extend to any desired length
- Reinforced hinged lid for easy cable placement
- With standard ramps
- Patented 5-bar tread surface for maximum traction
- Modular interlocking design for easy setup
- Custom cable protectors are available. [Get a quote here.](#)

Description

Guard Dog® low-profile models are the most compact top-loading cable protectors on the market. These protectors provide a safe and easy crossing for vehicle and pedestrian traffic, while still maintaining a high load-bearing capacity for heavy equipment. The low-profile models are available with your choice of standard or ADA/DDA compliant ramps.

Custom cable protectors can be made with different colors and embossed logos. **[Get a quote with your specific requirements.](#)**

Specifications

Model No	GD5X75-O/B / GD5X75-B/B / GD5X75-O/BLU
Brand	Checkers Safety™
Quantity Included	1
Load Capacity Per Axle	68000 lbs
Load Capacity Per Tire	34000
Length (Inches)	36
Width (Inches)	33.3
Height (Inches)	1.25
Max Cable Outside Diameter (Inches)	0.75
Number of Channels	5-Channels
Connector Type	Dog Bone Connector
Channel Width	1.28

Prop 65

⚠️WARNING: This product can expose you to chemicals including Lead, Carbon Black, Chromium, Nickel Compounds, and Sulfur Dioxide, which are known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

Product Options

Color:	Orange Lid / Blue Base
	Orange Lid / Black Base
	Black Lid / Black Base