

MAGNETIC TRANSDUCER (Pin Type- $\phi 12.0$ mm)

External Circuitry Type

Shape


KSQ-706BP
KSQ-601BP



RoHS Compliant Available (eg.KSQG706BP,KSQG601BP)

| Model Number | KSQ-706BP | KSQ-601BP |
|---------------------------------------|-----------------------------|-----------------------------|
| Rated Voltage (Vo-p) | 1.5 | |
| Operating Voltage Range (Vo-p) | 1.0 ~ 2.0 | |
| Current Consumption (mA) | Max. 20 | Max. 35 |
| Coil Resistance (Ω) | 50.0 ± 7.5 | 16.0 ± 2.4 |
| Sound Pressure Level (dBA) | Min. 70dBA(Typical 75)@10cm | Min. 70dBA(Typical 76)@10cm |
| Rated Frequency (Hz) | 2048 | |
| Operating Temperature ($^{\circ}$ C) | -20 ~ +60 | |
| Storage Temperature ($^{\circ}$ C) | -30 ~ +70 | |
| Weight (Gram) | 2.0 | |
| Material | PPO | |


Dimension

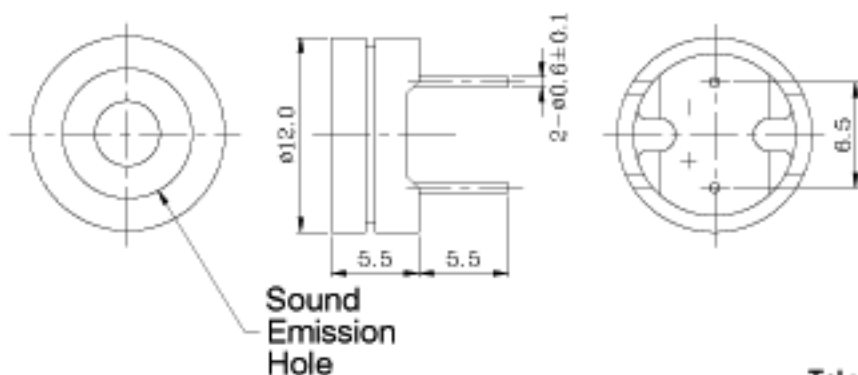

Tol : ± 0.5 Unit : mm

Characteristic

KSQ-706BP

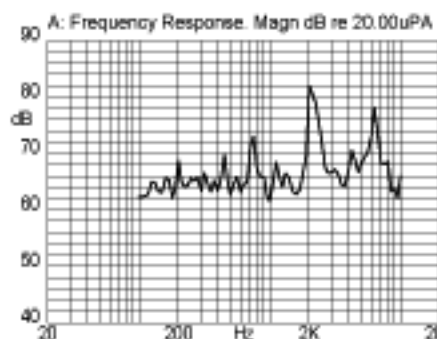

KSQ-601BP

