


M-3R, straight cut


- Cuts straight, left or right in light stock
- Perfect for home craftsman
- Non-slip serrated jaw of tough molybdenum steel allows for compound lever action
- Withstands strain of cutting heavy stock
- Spring-action for fast, effortless feed
- Handle of high tensile strength alloy steel exceeds hand power limit
- Handy hang-up hole
- Non-slip, textured grips and safety latch for superior control

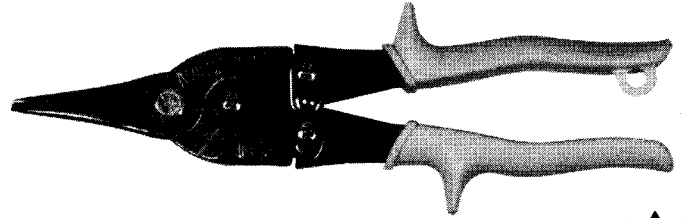

Cat. No.	UPC No.	← L →				Recommended max. capacity low carbon cold rolled steel	Pack Wt.		Shelf Pack
		Inch	mm	Inch	mm		oz	g	
M-3R Yellow Grips	037103580214	9 ³ / ₄	248	1 ¹ / ₂	38	18 Gauge Steel (0.049"/1.22mm)	84	2381	6

M6R, M7R Metalmaster® offset snips



- M-6R cuts left and straight
- M-7R cuts right and straight
- Offset blades keep hands clear of metal
- Non-slip serrated jaw of tough molybdenum steel allows for compound lever action
- Withstands strain of cutting heavy stock and tight curves
- Spring-action for fast, effortless feed
- Handle of high tensile strength alloy steel exceeds hand power limit
- Handy hang-up hole
- Non-slip, textured grips and safety latch for superior control

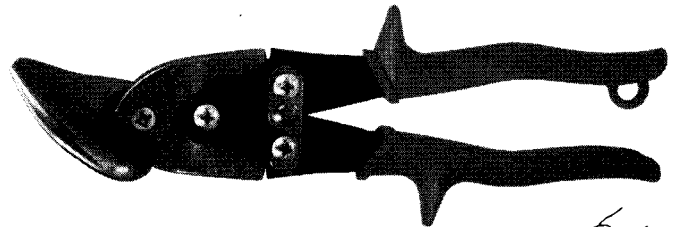

Cat. No.	UPC No.	← L →				Recommended max. capacity low carbon cold rolled steel	Pack Wt.		Shelf Pack
		Inch	mm	Inch	mm		oz	g	
M-6R Red Grips Circle Left	037103583376	9 ¹ / ₄	233	1 ¹ / ₄	32	18 Gauge Steel (0.049"/1.22mm)	84	2381	6
M-7R Green Grips Circle Right	037103583383	9 ¹ / ₄	233	1 ¹ / ₄	32	18 Gauge Steel (0.049"/1.22mm)	84	2381	6

M1R-S1, M2R-S1 Metalmaster® special series

 - M1R-S1 cuts left, M2R-S1 cuts right
- Specially hardened to cut exotic metals
- Non-slip serrated jaw of tough molybdenum steel allows for compound lever action
- Withstands strain of cutting heavy stock and tight curves
- Spring-action for fast, effortless feed
- Handle of high tensile strength alloy steel exceeds hand power limit
- Handy hang-up hole
- Non-slip, textured grips and safety latch for superior control

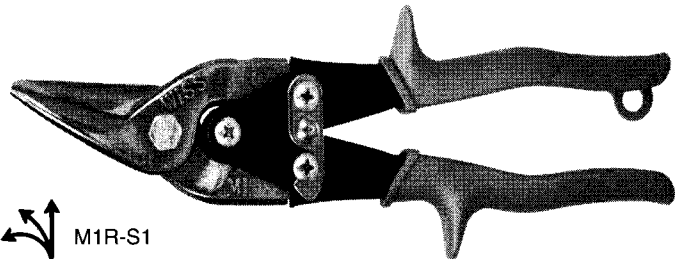

Cat. No.	UPC No.	← L →				Recommended max. capacity low carbon cold rolled steel	Pack Wt.		Shelf Pack
		Inch	mm	Inch	mm		oz	g	
M1R-S1 Blue Grips/cuts left	037103580139	9 ³ / ₄	248	1 ³ / ₈	35	18 Gauge Stainless Steel (0.049"/1.22mm)	84	2381	6
M2R-S1 Blue Grips/cuts right	037103580191	9 ³ / ₄	248	1 ³ / ₈	35	18 Gauge Stainless Steel (0.049"/1.22mm)	84	2381	6