


CONEX PUSH FITTINGS

Parallel male straight adaptor - RPD
MG

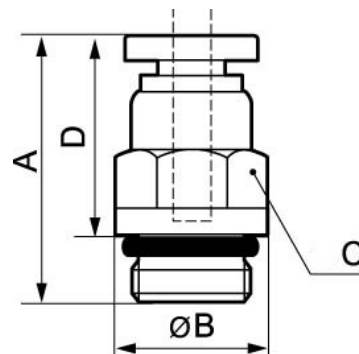

Min / Max operating pressure

0 / 10 bar

Min. / Max temperature

0 / 60 °C

Part number	Male thread	Dim. A (mm)	Dim. B (mm)	Dim. C (mm)	Dim. D (mm)
RPD MG04M5	M5	21.5	12	10	17.5
RPD MG0400	G1/8	20	14	12	14.5
RPD MG0401	G1/4	19	16.5	14	13
RPD MG05M5	M5	24	14	12	20
RPD MG0500	G1/8	24	14	12	18.5
RPD MG0501	G1/4	21	16.5	14	15
RPD MG0502	G3/8	21	20	17	14.5
RPD MG0503	G1/2	22.5	22	19	14.5
RPD MG06M5	M5	24	14	12	20
RPD MG0600	G1/8	24	14	12	18.5
RPD MG0601	G1/4	21	16.5	14	15
RPD MG0602	G3/8	21	20	17	20.5
RPD MG0603	G1/2	22.5	22	19	14.5
RPD MG0800	G1/8	25.5	16.5	14	20
RPD MG0801	G1/4	22	16.5	14	16
RPD MG0802	G3/8	21	20	17	14.5
RPD MG0803	G1/2	22.5	22	19	14.5
RPD MG1000	G1/8	27.8	20	17	22.3
RPD MG1001	G1/4	27.8	20	17	21.8
RPD MG1002	G3/8	25.8	22	19	19.3
RPD MG1003	G1/2	26.3	25	21	18.3
RPD MG1201	G1/4	30	22	19	24
RPD MG1202	G3/8	26.5	22	19	20
RPD MG1203	G1/2	28	25	21	20
RPD MG1402	G3/8	30.8	25.5	22	24.3
RPD MG1403	G1/2	28	28	24	20
RPD MG1602	G3/8	33	28	24	26.5
RPD MG1603	G1/2	34.5	28	24	26.5