



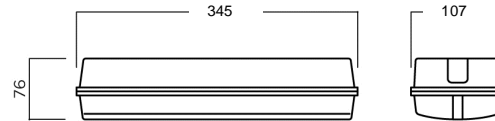

## Data Specification Sheet

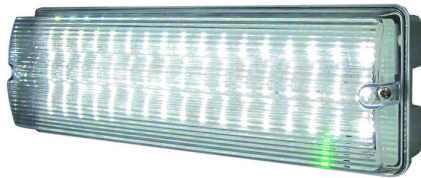

### 6Watt LED IP65 Emergency Bulkhead

<b>ML Accessories Code</b>	<b>EMLED1</b>
<b>Description</b>	<b>IP65 6 watt LED polycarbonate bulkhead 3 hour maintained/ non-maintained</b>
<b>Finishes available</b>	White base Prismatic diffuser
<b>Overall dimensions (mm) Length – Width - Depth</b>	(L)345mm (W)107mm (D)76mm
<b>Product Weight</b>	1.2kg (M)
<b>Voltage (V)</b>	220-230V 50-60Hz
<b>Lamp Type</b>	Non replaceable multi LED
<b>Charge Time (Initial)</b>	24 hours
<b>Discharge Duration (2 x sub C cell)</b>	3 Hours
<b>Class</b>	Class I. Must be Earthed
<b>IP</b>	IP65
<b>Circuit Power</b>	6.5 watts
<b>Temperature Range</b>	-10 to +30°C
<b>Origin of Manufacture</b>	China
<b>Main materials:</b>	
• <b>Chassis (gear tray)</b>	Powder Coated Pressed Steel
• <b>Body</b>	Self extinguishing Polycarbonate
• <b>Diffuser</b>	Self extinguishing Polycarbonate
• <b>Gasket</b>	1 piece Rubber
<b>Method of fix</b>	Direct fixing . Screws provided
<b>Instruction Sheet</b>	Yes
<b>Electrical Connections</b>	Screw terminals
<b>Running Gear</b>	Electronic
<b>F mark</b>	Yes
<b>CE mark</b>	Yes
<b>Quality Assurance System</b>	Yes ISO 9001 QMS
<b>Batch coding details on product</b>	Yes
<b>Certificate of Conformity (Held on File)</b>	Yes
<b>Manufactured in accordance to:</b>	EN55015. EN61547. EN61000-3-2. EN61347-2-7. EN61347-2-3 BSEN60598

ML Accessories Ltd. reserves the right to withdraw, improve or modify any design without prior notification.  
ML Accessories Ltd. cannot be held responsible for the incorrect application of any product.