


Safety light curtain

OYA1360-90-2-12-P-1

For 8-pole sockets the core colours are not standardised.
Please note the wiring of the sensor and the sockets (see data sheet).

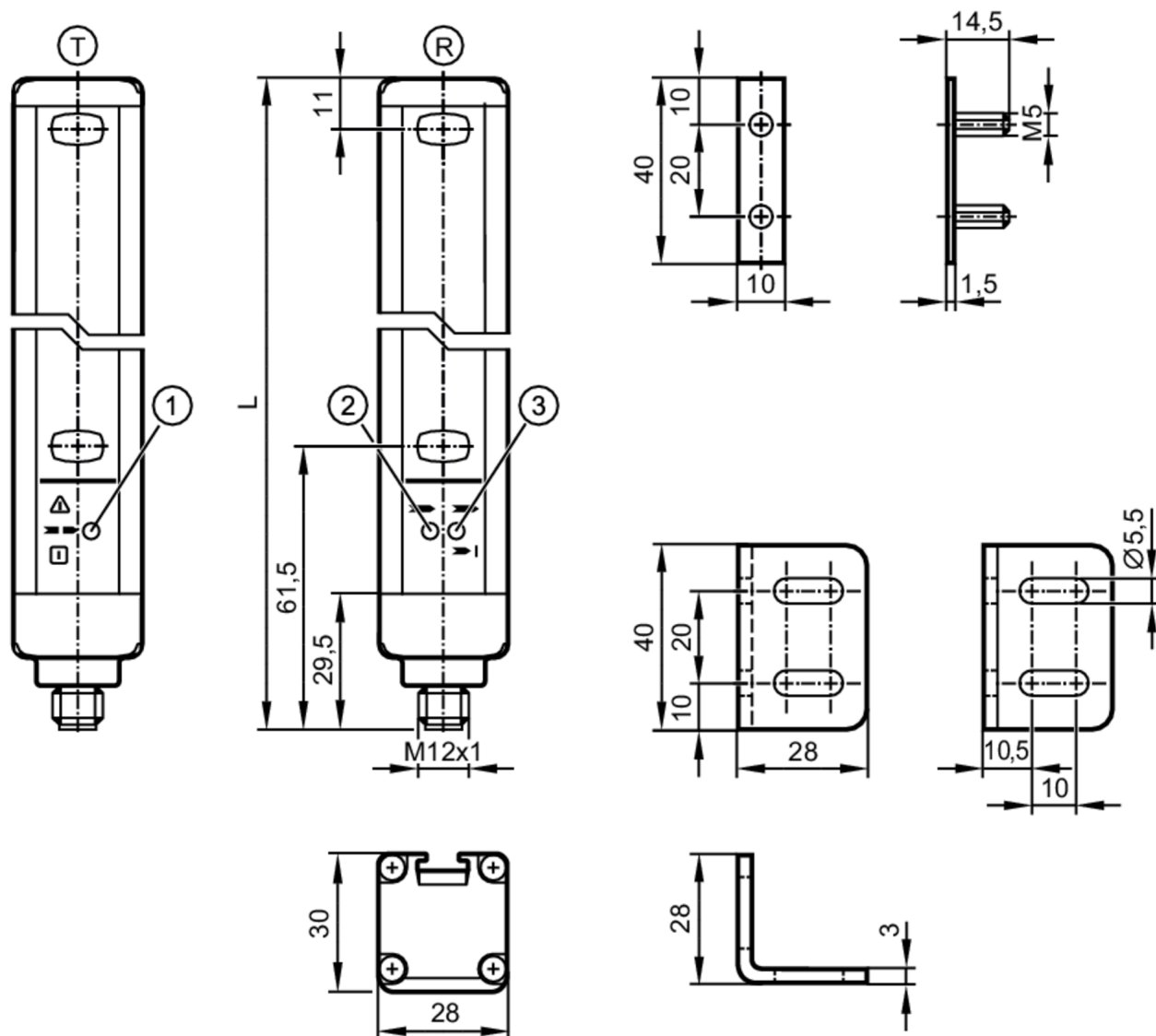

- | | |
|---|---------------------------------------|
| T | transmitter |
| R | receiver |
| 1 | LED three-colour red / green / orange |
| 2 | LED yellow |
| 3 | LED 2-colour red/green |



Product characteristics

Type of light	infrared light
---------------	----------------

Application

Protective function	access prevention bodies or parts of bodies
---------------------	---

Electrical data

Operating voltage tolerance	[%]	20
-----------------------------	-----	----



Safety light curtain

OYA1360-90-2-12-P-1

Operating voltage	[V]	24 DC
Protection class		III
Reverse polarity protection		yes
Power-on delay time	[s]	< 2
Type of light		infrared light
Wave length	[nm]	950
Receiver		
Current consumption	[mA]	83
Transmitter		
Current consumption	[mA]	42
Outputs		
Electrical design		PNP
Number of OSSD outputs		2
Max. current load per OSSD output	[mA]	400; (24 V)
Short-circuit protection		yes
Detection zone		
Protected area height	[mm]	1360
Resolution (detection capacity d)	[mm]	90
Protection area width (low light intensity)	[m]	0...4
Protection area width (high light intensity)	[m]	3...12
Response times		
Response time	[ms]	6.5
Operating conditions		
Applications		class C to EN 60654-1 weatherproof application
Ambient temperature	[°C]	-10...55
Storage temperature	[°C]	-20...70
Max. relative air humidity	[%]	95
Protection		IP 65; IP 67
Tests / approvals		
EMC	IEC 61496-1	
Shock resistance	IEC 61496-1	
Vibration resistance	IEC 61496-1	
Safety classification		
ESPE type (IEC 61496-1)		2
Complies with the requirements		ISO 13849-1: 2015 category 2, PL c IEC 62061 SIL 1
Mission time TM	[h]	175200
PFH	[1/h]	3,4E-08
Mechanical data		
Weight	[g]	4654
Dimensions	[mm]	1413 x 28 x 30

OY099S




Safety light curtain

OYA1360-90-2-12-P-1


Materials	housing: aluminium; front pane: PC	
Length L [mm]	1413	
Displays / operating elements		
Display	transmitter	1 x LED
	receiver	2 x LED
Accessories		
Items supplied	mounting bracket: 6	
	slot nuts: 6	
	Nuts	
Remarks		
Pack quantity	1 pcs.	

Electrical connection - receiver

Connector: 1 x M12; coding: A; Maximum cable length: 100 m; for wire cross-section 0.34 mm²

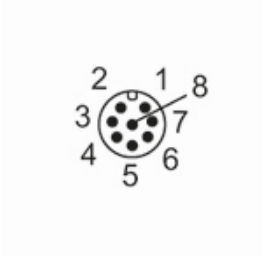

Connection

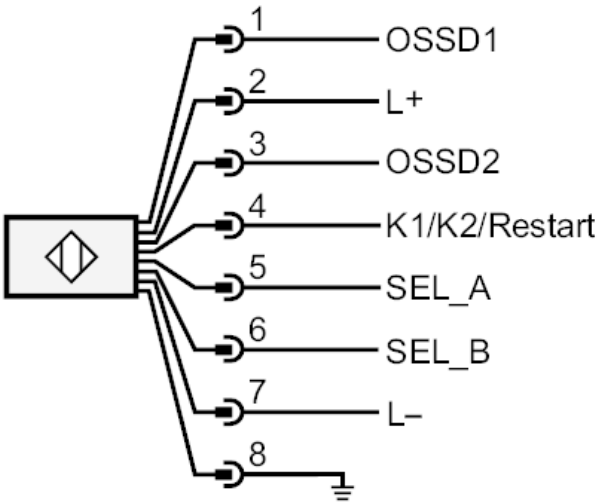

Safety light curtain

OYA1360-90-2-12-P-1

Electrical connection - transmitter

Connector: 1 x M12; coding: A



Connection

