

2004

TOOL TROLLEY
Body:

- Dimensions: H 985 x W 775 x D 475 mm
- Working platform in ABS, with 3 compartments for small parts
- Storage compartment with perforated sheet (Euro perforation 10 x 38 mm), two removable drawers for small parts and door on the handle side
- With handle for easy pushing, pulling and turning
- Front side with square perforation 10 x 38 mm to fix hooks and tools
- Heel and impact protection for your safety
- Sheet steel, corrosion resistant and scratch-proof powder-coated, GEDORIT blue

Drawers:

- Central locking with cylinder lock
- Wide drawers (W 480 x D 400 mm) fully extendable, removable
- Each drawer and storage compartment with safety locking, single-hand operation
- Ball-bearing guide rails
- Can be individually equipped with length and crosswise dividers (can be ordered individually)
- Load capacity per drawer 40 kg, bottom heavy-duty drawer 60 kg (apart from 2004 1000)
- Sheet steel, corrosion resistant and scratch-proof powder-coated, GEDORIT silver

GEDORE High-performance chassis:

- Total load capacity 500 kg
- 2 high-performance wheels on roller bearings (fixed castors Ø 200 mm)
- 2 smooth running wheels on ball bearings (swivel castors Ø 100 mm), both with total brake
- The GEDORE axle construction secures smooth running, manoeuvrability and track-keeping also in case of maximum loads

Accessories:



- Length- (LD) and crosswise (CD) dividers from zinc-plated sheet steel

Options:

- Can be equipped with GEDORE tool modules (1500 ES/1500 CT)
- Optionally extendable with GEDORE tool chests, rear panels and tool holders
- Further drawer combinations on request
- Special colours and designs available on request
- Delivery without tools and accessories



2004 0511

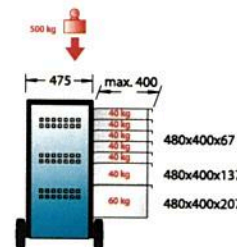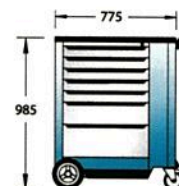

	H	W	D	LD	CD		Code	No.
10 drawers:	985	775	475	15x	3x	94.0	1640690	2004 1000
10x type 1, H = 67 mm								
9 drawers:	985	775	475	15x	3x	91.0	1640704	2004 0810
8x type 1, H = 67 mm								
1x type 2, H = 137 mm								
8 drawers:	985	775	475	10x	2x	86.0	1640712	2004 0701
7x type 1, H = 67 mm								
1x type 3, H = 207 mm								
8 drawers:	985	775	475	10x	2x	88.0	1640720	2004 0620
6x type 1, H = 67 mm								
2x type 2, H = 137 mm								
7 drawers:	985	775	475	10x	2x	84.0	1640739	2004 0511
5x type 1, H = 67 mm								
1x type 2, H = 137 mm								
1x type 3, H = 207 mm								
6 drawers:	985	775	475	6x	2x	82.0	1640755	2004 0321
3x type 1, H = 67 mm								
2x type 2, H = 137 mm								
1x type 3, H = 207 mm								
5 drawers:	985	775	475	3x	2x	75.0	1640763	2004 0131
1x type 1, H = 67 mm								
2x type 2, H = 137 mm								