


PRODUCT-DETAILS

432RU6

Socket-outlet, panel mounting, 6h, 32A, IP44, unified flange, straight, 3P+N+E

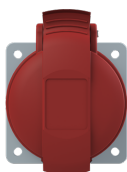

General Information

Extended Product Type	432RU6
Product ID	2CMA193259R1000
EAN	7392696932592
Catalog Description	Socket-outlet, panel mounting, 6h, 32A, IP44, unified flange, straight, 3P+N+E
Long Description	Panel mounted socket, earthing sleeve position 6h, rated current 32A, IP44 splashproof, unified flange, straight, 3-poles+neutral+earth, frequency 50-60 Hz, color code Red

Ordering

E-Number (Sweden)	E2416660
E-Number (Finland)	2421246
E-Number (Norway)	1547353
EAN	7392696932592
Country of Origin	Czech Republic (CZ)
Minimum Order Quantity	10 piece

Dimensions

Product Net Width	75 mm
Product Net Height	102 mm

Product Net Weight	0.24 kg
Mechanical Drawings	9AKK107991A3863

Container Information

Package Level 1 Width	154 mm
Package Level 1 Depth / Length	182 mm
Package Level 1 Height	378 mm
Package Level 1 Gross Weight	2.4 kg
Package Level 1 EAN	739269662598
Package Level 1 Units	box 10 piece
Package Level 2 Width	800 mm
Package Level 2 Depth / Length	1200 mm
Package Level 2 Height	900 mm
Package Level 2 Gross Weight	1100 kg
Package Level 2 EAN	7392696080071
Package Level 2 Units	pallet (lift) 450 piece

Environmental

RoHS Status	Following EU Directive 2011/65/EU
-------------	-----------------------------------

Certificates and Declarations (Document Number)

Declaration of Conformity - CE	2CMC700005D0001
Environmental Information	2CMC000056M0000
RoHS Information	2CMC700005D0001
SEMKO Certificate	1613211
REACH Declaration	2CMC700005D0001

Additional Information

Additional Information	3P+N+E
Ambient Temperature	-25 ... 40 °C
Cable Cross-Section	2.5 ... 10 mm ²
Cable Diameter	13 ... 21.5 mm
Color	Red
Connection Type	Screw
Degree of Protection	IP44
Frequency (f)	50 Hz 60 Hz
Function	Panel mounted socket
Housing Material	Plastic (PA)

Invoice Description	Ind. P&S#432RU6
Mounting Holes	60-61x60-61
Mounting Type	Unified straight flange
Number of Poles	5
Order Multiple	10 piece
Product Main Type	ERU
Product Name	Panel mounted socket
Protection Type	Splashproof
Rated Current (I_n)	32 A
Rated Frequency (f)	50...60 Hz
Rated Voltage (U_r)	200/346 ... 240/415 V
Recommended Screw Driver	PH2
Standards	IEC 60309-1, -2
Suitable For	Socket Outlets for Panel Mounting
Suitable for Product Class	IEC Industrial Plugs and Sockets
Instructions and Manuals	2CMC700014C0016
RAL Number	RAL 7001 - Silver Grey

Classifications

eClass	27440504
UNSPSC	39121406

Technical

Wire Size	12 ... 10 AWG
Tightening Torque	WireClamp1.2 N·m

Categories

Low Voltage Products and Systems → Industrial Plugs and Sockets → Easy & Safe → Socket Outlets for Panel Mounting

